

EMC-SUPPRESSORS FOR VALVE PLUG

Diode and LED, 24VDC/60VA/W

Art.No.: 3224681

Weight: 0.014 kg

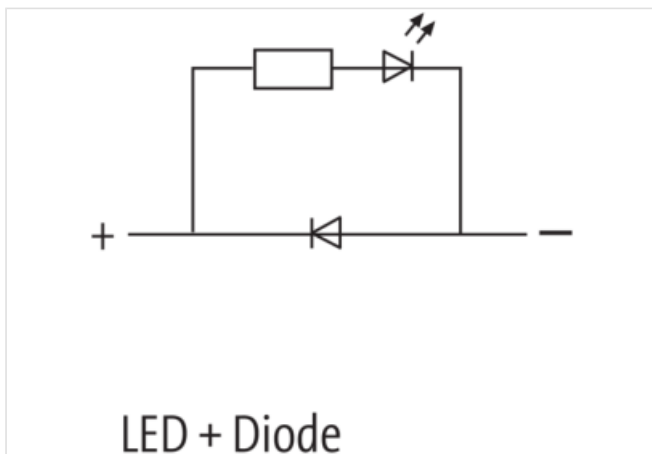
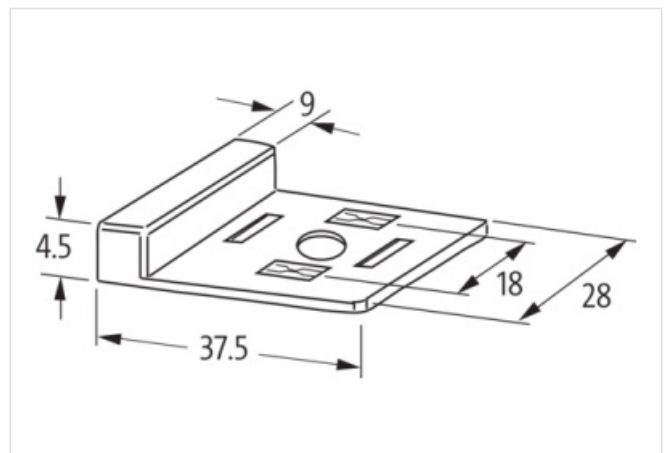
Country of origin: DE

Model designation: MLA LEDG TVS Diode 24V

24 V AC/DC

Diode + LED (green)

Remove plug gasket when fitting adapter. Other LED colors on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

MLA LEDG TVS Diode 24V

Commercial data

URL Webshop

<https://shop.murrelektronik.com/3224681>

GTIN	4048879011310
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879011310
Packaging unit	1

Electrical data

Drop-out delay time max.	200 ms
Holding power max.	60 W

Electrical data | Supply

Cut-off peak voltage max.	1 V
---------------------------	-----

Electrical data | Input

Input voltage AC min.	20 V
Input voltage AC max.	27 V
Input voltage DC min.	20 V
Input voltage DC max.	27 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Installation

Type of contact	A
Contact distance	18 mm

Mechanical data | Material data

Material housing	PUR
Material contact	Bronze
Coating contact	silver-plated

Mechanical data | Mounting data

Height	4,5 mm
Width	37,5 mm
Depth	28 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C