

MODLINK MSDD DBL COMBI INSERT GERMANY


RCD opening

Art.No.: 4000-68000-4300000
Weight: 0.096 kg
Country of origin: DE
Model designation: Fr.Modul-CF-250-16-PT+RCD cutout

1× Germany (VDE) white
1× FI cut-out

Link to Product

Illustration

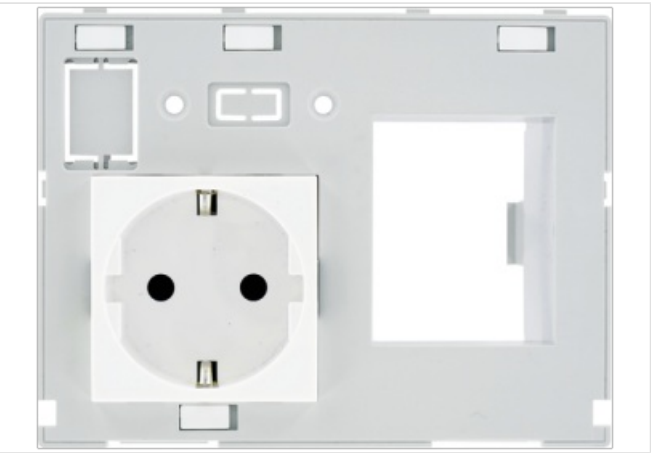

Product may differ from Image



Header

Material short textFr.Modul-CF-250-16-PT+RCD cutout

Commercial data

URL Webshop	https://shop.murrelektronik.com/4000-68000-4300000
GTIN	4048879369350
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-7.1	27189217
ECLASS-8.0	27189217
ECLASS-8.1	27189217
ECLASS-9.0	27182806
ECLASS-9.1	27189217
ECLASS-10.0.1	27182806
ECLASS-10.1	27182806
ECLASS-11.0	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ECLASS-13.0	27182806
ECLASS-14.0	27182806

ETIM-5.0	EC000020
ETIM-6.0	EC000020
ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
EAN	4048879369350
Packaging unit	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Ambient temperature (storage, transport)	-10 °C ... 60 °C
--	------------------

Shielding plate

Connection information	Threaded hole M4
Tightening torque	0,9 Nm
Tightening torque tolerance	± 0,1 Nm

Germany (VDE)

Connection	Spring clamp terminals FK
No. of poles	PE
Connections per pole	2
Protection contact present	Yes
Connection cross section max.	2,5 mm ²
AWG number max.	14
Operating voltage AC	250 V
Operating current	16 A