

MODLINK MSDD DBL COMBI INSERT AUMALERIALIA

1xRJ45 fem./fem. + RCD opening

Art.No.: 4000-68000-4360001

Weight: 0.110 kg

Country of origin: CN

Model designation: Fr.Modul-I-240-15-SC+RJ45+RCD cutout


1× Australia

1× RJ45, 8-pole metal, CAT5e (female/female)

1× FI cut-out

Link to Product

Illustration

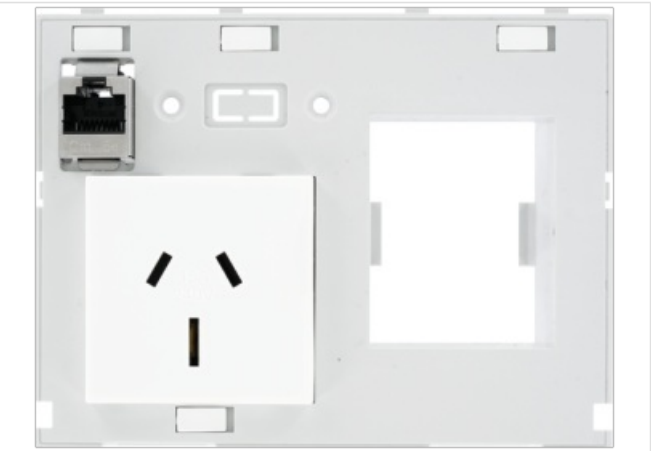

Product may differ from Image



Header	
Material short text	Fr.Modul-I-240-15-SC+RJ45+RCD cutout
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-68000-4360001
GTIN	4048879384629
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-7.1	27189217
ECLASS-8.0	27189217
ECLASS-8.1	27189217
ECLASS-9.0	27182806
ECLASS-9.1	27189217
ECLASS-10.0.1	27182806
ECLASS-10.1	27182806
ECLASS-11.0	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ECLASS-13.0	27182806

ECLASS-14.0	27182806
ETIM-5.0	EC000020
ETIM-6.0	EC000020
ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
EAN	4048879384629
Packaging unit	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Ambient temperature (storage, transport)	5 °C ... 40 °C
--	----------------

Australia

Connection	Screw terminals SK
No. of poles	PE
Connections per pole	2
Protection contact present	Yes
Connection cross section max.	4 mm ²
AWG number max.	12
Operating voltage AC	240 V
Operating current	15 A

RJ45

Family construction form	RJ45
Looking techniques	Snap-in connector
Cable category min.	Cat5e
Family type Back side	RJ45
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA