

## MODLINK MSDD DBL COMBI INSERT CHINA

1xRJ45 fem./fem. + RCD opening

Art.No.: 4000-68000-4380001


Weight: 0.164 kg

Country of origin: DE

Model designation: Fr.Modul-I-250-10-SC+RJ45+RCD cutout

### Link to Product

#### Illustration

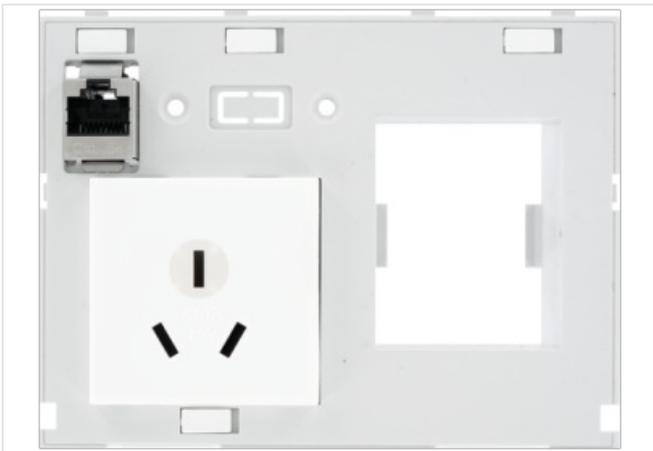

Product may differ from Image



#### Header

Material short text Fr.Modul-I-250-10-SC+RJ45+RCD cutout

#### Commercial data

URL Webshop	<a href="https://shop.murrelektronik.com/4000-68000-4380001">https://shop.murrelektronik.com/4000-68000-4380001</a>
GTIN	4048879618991
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-7.1	27189217
ECLASS-8.0	27189217
ECLASS-8.1	27189217
ECLASS-9.0	27182806
ECLASS-9.1	27189217
ECLASS-10.0.1	27182806
ECLASS-10.1	27182806
ECLASS-11.0	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ECLASS-13.0	27182806
ECLASS-14.0	27182806
ETIM-5.0	EC000020
ETIM-6.0	EC000020

ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
EAN	4048879618991
Packaging unit	1

**Mechanical data | Mounting data**

Height	88 mm
Width	116 mm
Depth	69 mm

**Environmental characteristics | Climatic**

Ambient temperature (storage, transport)	5 °C ... 40 °C
--	----------------

**China (CCC)**

Connection	Screw terminals SK
No. of poles	PE
Connections per pole	2
Protection contact present	Yes
Connection cross-section solid max.	4 mm <sup>2</sup>
Connection cross-section stranded/fine-stranded max.	4 mm <sup>2</sup>
Operating voltage AC	250 V
Operating current	10 A

**RJ45**

Family construction form	RJ45
Looking techniques	Snap-in connector
Cable category min.	Cat5e
Family type Back side	RJ45
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA