

**Modlink MSDD-set: Frame 4000-68213-0000000,**

insert 4000-68000-1210000

Art.No.: 4000-68213-1210000


Weight: 0.286 kg

Country of origin: CZ

Model designation: MSDD\_1MVIPK\_RJ45+BL\_

**Link to Product**

### Illustration

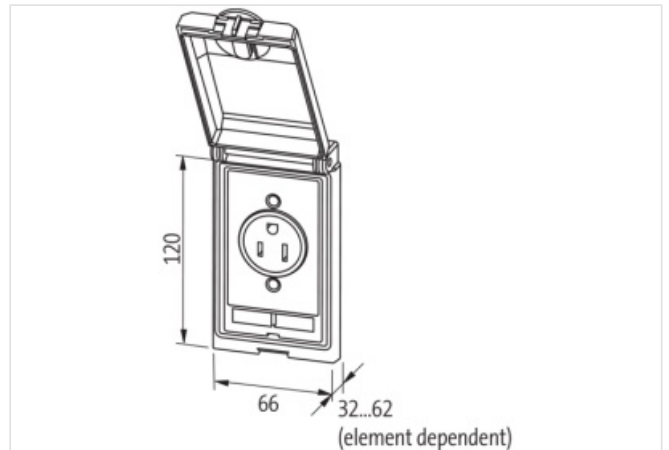

Product may differ from Image

## Header

Material short text MSDD\_1MVIPK\_RJ45+BL

## Commercial data

|             |                                                                                                                     |
|-------------|---------------------------------------------------------------------------------------------------------------------|
| URL Webshop | <a href="https://shop.murrelektronik.com/4000-68213-1210000">https://shop.murrelektronik.com/4000-68213-1210000</a> |
| GTIN        | 4048879033435                                                                                                       |
| ECLASS-6.0  | 27189217                                                                                                            |
| ECLASS-6.1  | 27189217                                                                                                            |
| ECLASS-7.0  | 27189217                                                                                                            |
| ECLASS-7.1  | 27189217                                                                                                            |
| ECLASS-8.0  | 27189217                                                                                                            |
| ECLASS-8.1  | 27189217                                                                                                            |
| ECLASS-9.0  | 27182806                                                                                                            |

The information in this Product-PDF has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-09

|                       |               |
|-----------------------|---------------|
| ECLASS-9.1            | 27189217      |
| ECLASS-10.0.1         | 27182806      |
| ECLASS-10.1           | 27182806      |
| ECLASS-11.0           | 27182806      |
| ECLASS-11.1           | 27182806      |
| ECLASS-12.0           | 27182806      |
| ECLASS-13.0           | 27182806      |
| ECLASS-14.0           | 27182806      |
| ETIM-5.0              | EC002625      |
| ETIM-6.0              | EC002625      |
| ETIM-7.0              | EC002625      |
| ETIM-8.0              | EC002625      |
| customs tariff number | 85389099      |
| EAN                   | 4048879033435 |
| Packaging unit        | 1             |
| customs tariff number | 85389099      |
| EAN                   | 4048879033435 |
| Packaging unit        | 1             |

**Frame**

|                                               |                       |
|-----------------------------------------------|-----------------------|
| Material housing                              | Fine zinc die casting |
| Material lid                                  | PC                    |
| Coating housing                               | surface finished      |
| Color cover                                   | transparent           |
| Suitable for installation wall thickness min. | 1 mm                  |
| Suitable for installation wall thickness max. | 5 mm                  |
| Degree of protection (EN IEC 60529)           | IP65                  |
| Operating temperature min.                    | -10 °C                |
| Operating temperature max.                    | 60 °C                 |
| Storage temperature min.                      | -25 °C                |

**RJ45**

|                                       |                   |
|---------------------------------------|-------------------|
| Family construction form              | RJ45              |
| Looking techniques                    | Snap-in connector |
| Cable category min.                   | Cat5e             |
| Family type Back side                 | RJ45              |
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Current operating max. (UL)           | 175 mA            |