

EOL - Modlink MSDD set contains: Frame 4000-68513-0000001


discontinued - End of Life Date: 2024-12-31


Art.No.: 4000-68513-0510001

Weight: 0.125 kg

Country of origin: DE

Model designation: X MSDD_1metallic_2X15BU_

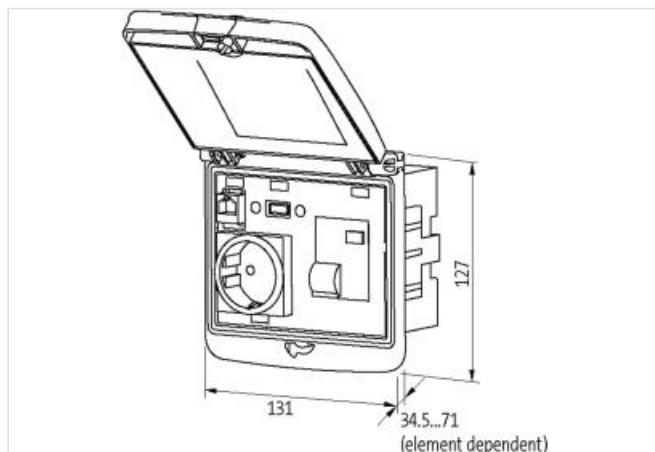[**Link to Product**](#)
Illustration

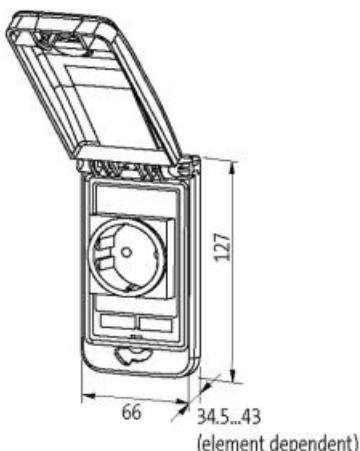


Product may differ from Image



Commercial data

ECCLASS-6.0	27189217
ECCLASS-7.0	27189217
ECCLASS-8.0	27189217
ECCLASS-9.0	27189217
ETIM-5.0	EC002625
customs tariff number	85366990
EAN	4048879814829
Packaging unit	1

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Material housing	PA
Color housing	black
Material lid	ABS
Color cover	metallic

SUB-D15

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V

Current operating max. (UL)	175 mA
Family construction form	SUB-D15
Family type Back side	SUB-D15
Gender	female
Gender Rear	Solder connection
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)
No. of poles	15