

Modlink MSDD set contains:Frame 4000-68513-0000001


Insert 4000-68000-4070000


Art.No.: 4000-68513-4070001

Weight: 0.134 kg

Country of origin: US

Model designation: MSDD_1metallic_NEMA 5-15R löt, 2xRJ45 Bu

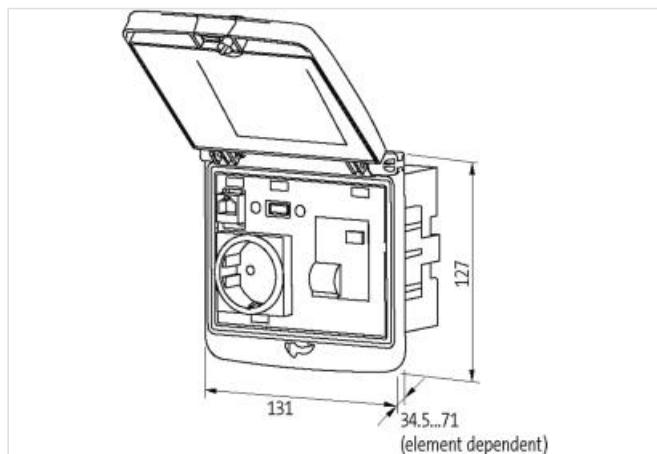[Link to Product](#)
Illustration

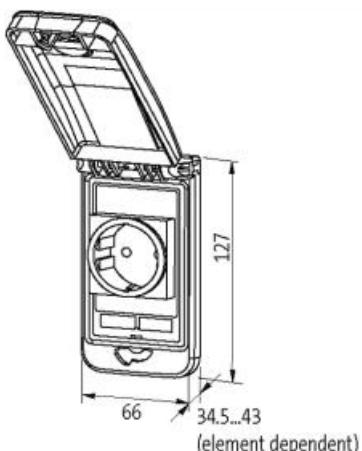


Product may differ from Image



Commercial data

ECCLASS-6.0	27189234
ECCLASS-7.0	27189234
ECCLASS-8.0	27189234
ECCLASS-9.0	27189234
ETIM-5.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
customs tariff number	85366990
EAN	4048879691789
EAN	4048879691789
EAN	4048879691789
Packaging unit	1
Packaging unit	1
Packaging unit	1

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Material housing	PA
Color housing	black
Material lid	ABS
Color cover	metallic

Fuse

Operating voltage AC	250 V
Operating voltage DC	32 V
Nominal current	3 A

Shielding plate

Connection information	Threaded hole M4
------------------------	------------------

Tightening torque	0,9 Nm
-------------------	--------

USA

Connection geometry	4.8 x 0.5 mm
Operating voltage AC	125 V
Operating current	15 A
Connection	Plug-solder connection
No. of poles	2 + PE
Protection contact present	yes

RJ45

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector