

MSDD pass-through RJ45 CAT5e femal/femal, design black

Neutral lid without logo

Art.No.: 4000-73000-0010001

Weight: 0.018 kg

Country of origin: CZ




Model designation: MSDD PT22-B RJ45 CAT5e F/F


Pass-through

1 × RJ45, 8-pole CAT5e (female/female)

[Link to Product](#)

Illustration

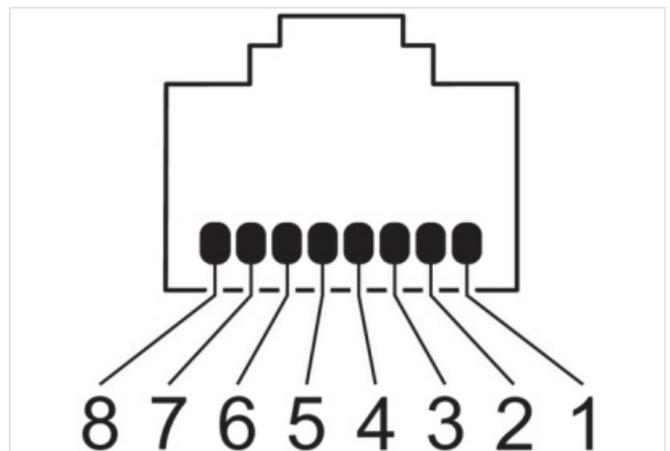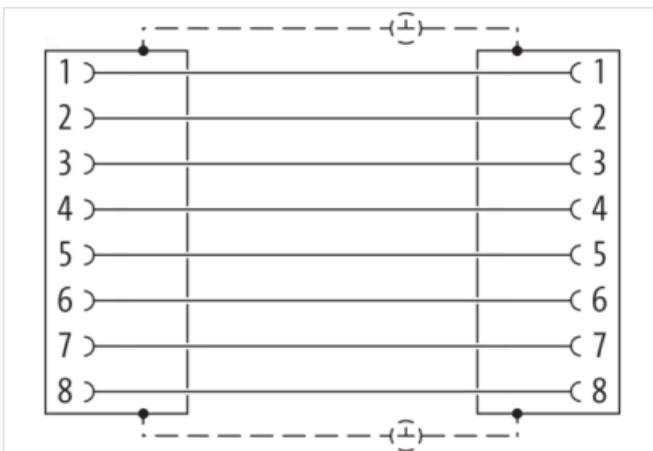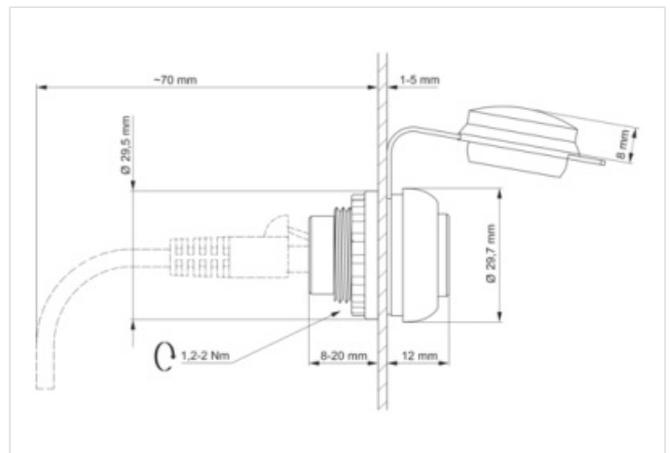

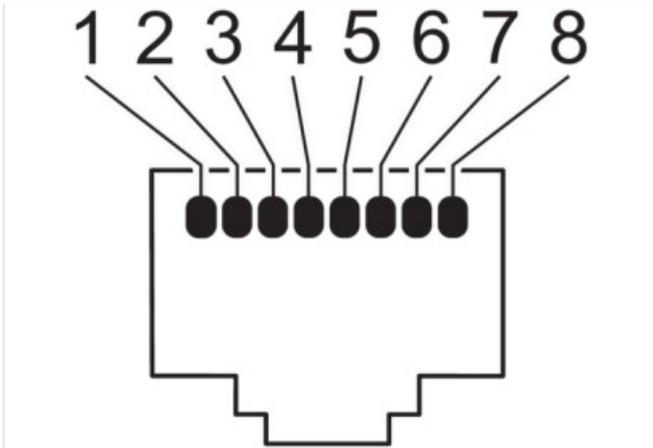

Product may differ from Image

**Header**

Material short text MSDD PT22-B RJ45 CAT5e F/F

Commercial dataURL Webshop <https://shop.murrelektronik.com/4000-73000-0010001>

GTIN 4065909035931

ECLASS-6.0 27143423

ECLASS-6.1 27143419

ECLASS-7.0 27440515

ECLASS-7.1 27440515

ECLASS-8.0 27440515

ECLASS-8.1 27440515

ECLASS-9.0 27440515

ECLASS-9.1 27440515

ECLASS-10.0.1 27440515

ECLASS-10.1 27440515

ECLASS-11.0 27440515

ECLASS-11.1 27440515

ECLASS-12.0 27440515

ECLASS-13.0 27440515

ECLASS-14.0 27440515

ETIM-5.0 EC002625

ETIM-6.0 EC002625

ETIM-7.0 EC002625

ETIM-8.0 EC002625

customs tariff number 85366990

EAN 4065909035931

Packaging unit 1

Electrical data | Supply

Operating voltage AC 24 V

Operating voltage DC 24 V

Operating current max. 1,5 A

Industrial Communication

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-08

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

Data transmission rate max. 1.000 Mbit/s

Installation | Connection

Family construction form RJ46

Gender female

Gender Rear female

Cable category min. Cat5e

Device protection

Shielded Yes

Device protection | Electrical

Degree of protection (EN IEC 60529) IP20, IP65

Protection NEMA 12, 3R, 4x, 4, 13, 2

Additional condition protection degree in closed state, inserted

Device protection | Mechanical

Mechanical endurance 750 cycles

Mechanical data | Mounting data

Depth 20 mm

Diameter 29,5 mm

Mounting depth 70 mm

Diameter cutout 22,5 mm

Approvals

UL 50E Yes