

MSDD pass-through USB 3.0 form A, 1.5 m cable, design silver

Art.No.: 4000-73000-0170000

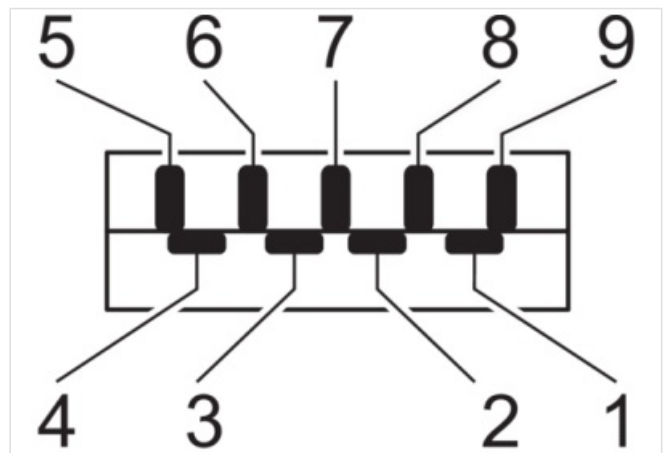
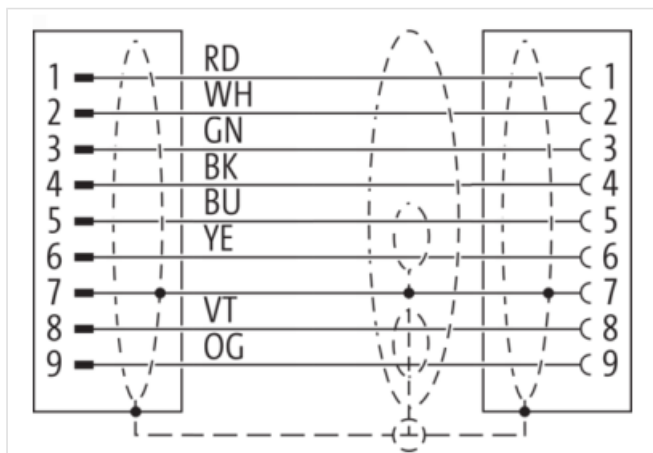
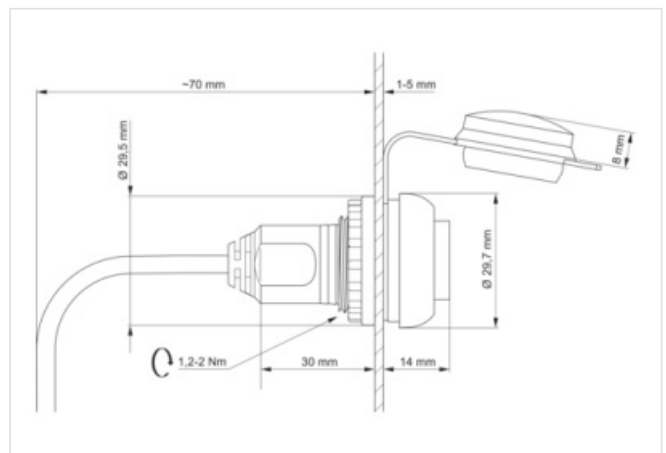
Weight: 0.098 kg

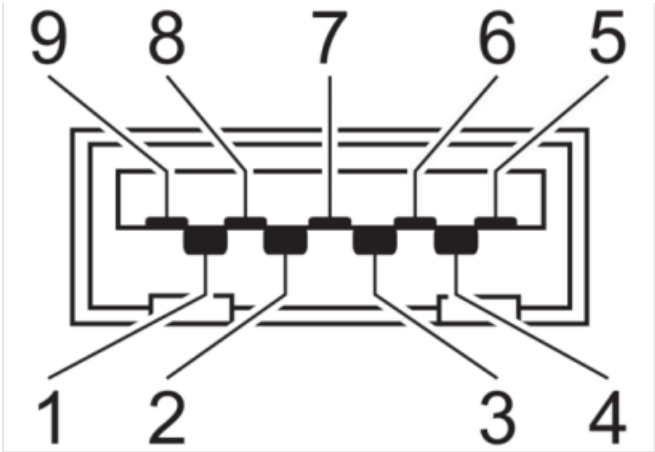
Country of origin: CZ

Model designation: MSDD PT22-S USB3.0 A/A F/M_1.5

Pass-through

1 × USB 3.0 (female/male/1.5 m cable) form A

[Link to Product](#)**Illustration**



Product may differ from Image



Header	
Material short text	MSDD PT22-S USB3.0 A/A F/M_1.5
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-73000-0170000
GTIN	4048879433419
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-7.1	27440515
ECLASS-8.0	27440515
ECLASS-8.1	27440515
ECLASS-9.0	27440515
ECLASS-9.1	27440515
ECLASS-10.0.1	27440515
ECLASS-10.1	27440515
ECLASS-11.0	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ECLASS-13.0	27440515
ECLASS-14.0	27440515
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85444290
EAN	4048879433419
Packaging unit	1
Electrical data Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial Communication	

Data transmission rate max.	5.000 Mbit/s
-----------------------------	--------------

USB specification	3.0
-------------------	-----

Device protection

Shielded	Yes
----------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
-------------------------------------	------------

Protection NEMA	12, 3R, 4x, 4, 13, 2
-----------------	----------------------

Additional condition protection degree	in closed state, inserted
--	---------------------------

Device protection | Mechanical

Mechanical endurance	1.500 cycles
----------------------	--------------

Mechanical data | Mounting data

Depth	30 mm
-------	-------

Diameter	29,5 mm
----------	---------

Mounting depth	70 mm
----------------	-------

Diameter cutout	22,5 mm
-----------------	---------

Approvals

UL 50E	Yes
--------	-----