

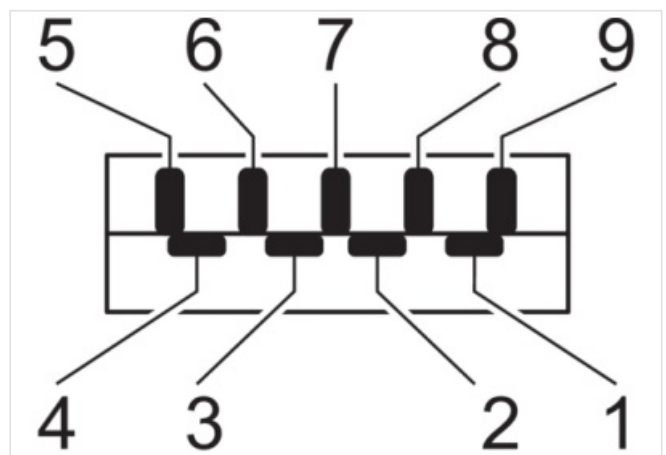
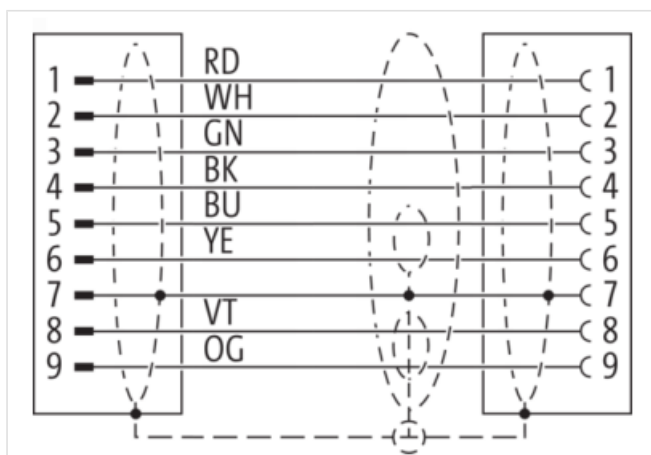
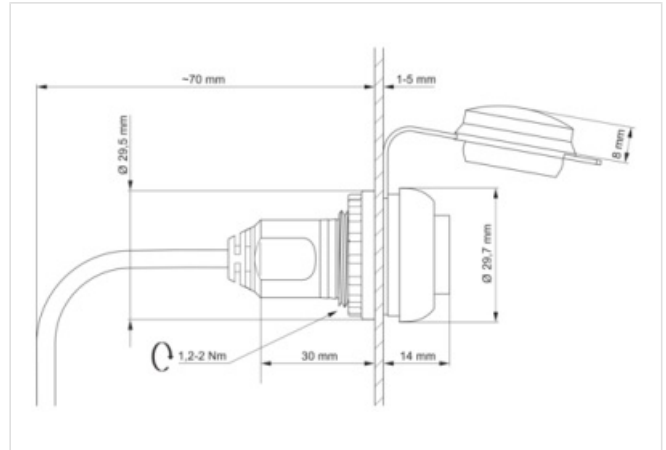
MSDD pass-through USB 3.0 form A, 3.0 m cable, design silver

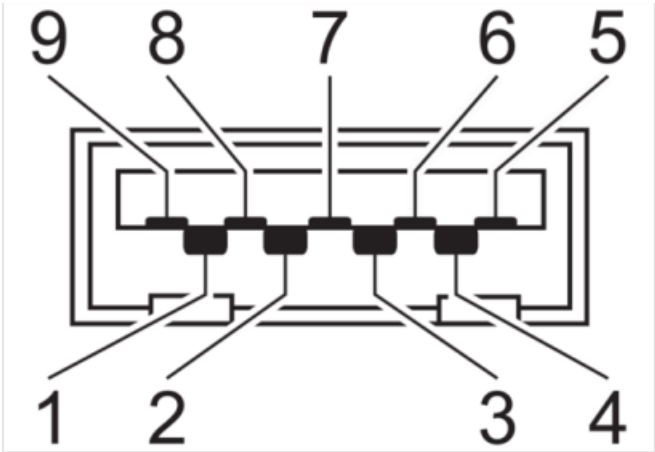
Art.No.: 4000-73000-0200000

Weight: 0.152 kg

Country of origin: CZ

Model designation: MSDD PT22-S USB3.0 A/A F/M_3.0

[Link to Product](#)
Illustration




Product may differ from Image



Header	
Material short text	MSDD PT22-S USB3.0 A/A F/M_3.0
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-73000-0200000
GTIN	4048879857000
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-7.1	27440515
ECLASS-8.0	27440515
ECLASS-8.1	27440515
ECLASS-9.0	27440515
ECLASS-9.1	27440515
ECLASS-10.0.1	27440515
ECLASS-10.1	27440515
ECLASS-11.0	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ECLASS-13.0	27440515
ECLASS-14.0	27440515
customs tariff number	85444290
EAN	4048879857000
Packaging unit	1
Electrical data Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial Communication	
Data transmission rate max.	5,000 Mbit/s
USB specification	3.0
Device protection	
Shielded	yes
Device protection Electrical	

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	12, 3R, 4x, 4, 13, 2
Additional condition protection degree	in closed state, inserted

Device protection | Mechanical

Mechanical endurance	1,500 cycles
----------------------	--------------

Mechanical data | Mounting data

Depth	30 mm
Diameter	29.5 mm
Mounting depth	70 mm
Diameter cutout	22.5 mm

Approvals

UL 50E	yes
--------	-----