

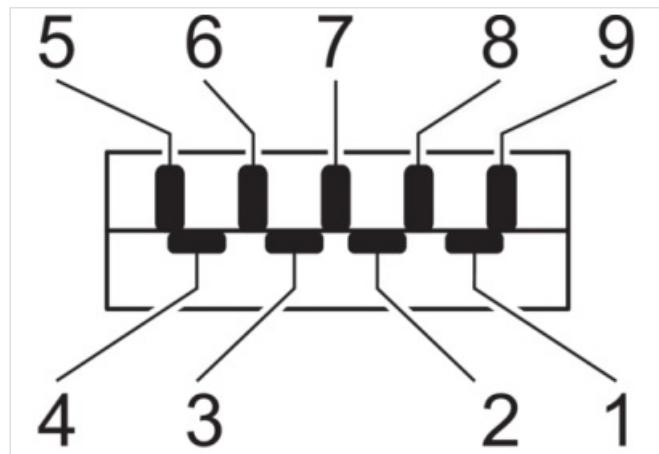
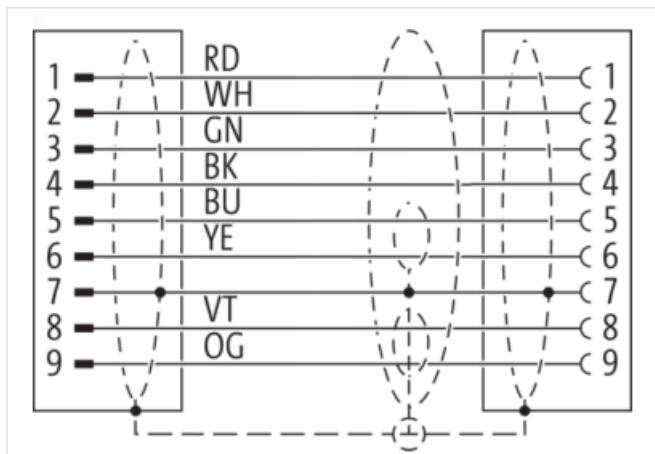
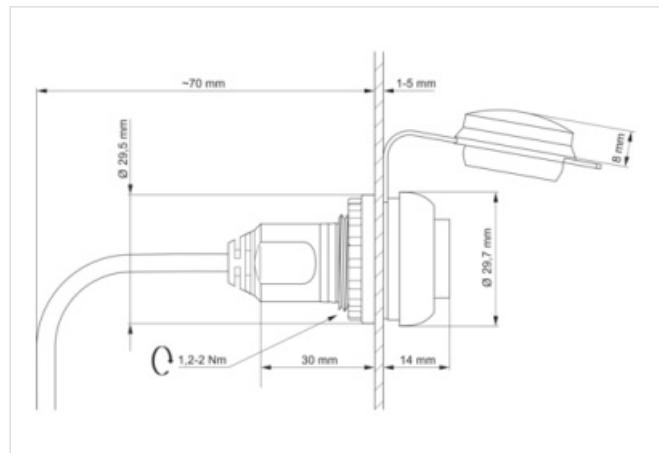
**MSDD pass-through USB 3.0 form A, 5.0 m cable, design silver**

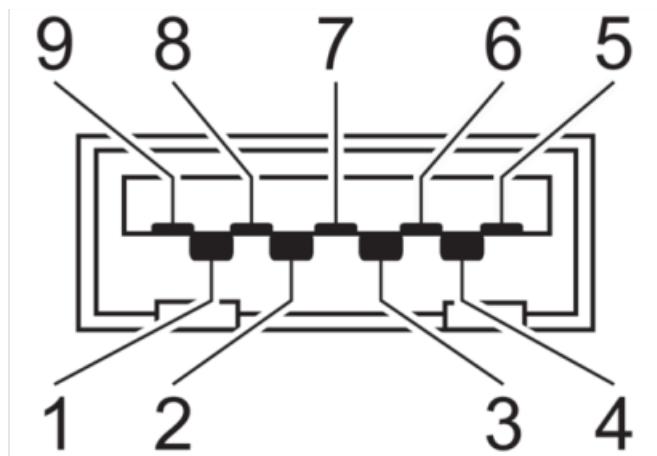
Art.No.: 4000-73000-0240000

Weight: 0.232 kg

Country of origin: CZ

Model designation: MSDD PT22-S USB3.0 A/A F/M\_5.0

[Link to Product](#)
**Illustration**




Product may differ from Image



#### Header

Material short text MSDD PT22-S USB3.0 A/A F/M\_5.0

#### Commercial data

URL Webshop	<a href="https://shop.murrelektronik.com/4000-73000-0240000">https://shop.murrelektronik.com/4000-73000-0240000</a>
GTIN	4048879857017
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-7.1	27440515
ECLASS-8.0	27440515
ECLASS-8.1	27440515
ECLASS-9.0	27440515
ECLASS-9.1	27440515
ECLASS-10.0.1	27440515
ECLASS-10.1	27440515
ECLASS-11.0	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ECLASS-13.0	27440515
ECLASS-14.0	27440515
customs tariff number	85444290
EAN	4048879857017
Packaging unit	1

#### Electrical data | Supply

Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA

#### Industrial Communication

Data transmission rate max.	5,000 Mbit/s
USB specification	3.0

#### Device protection

Shielded	yes
----------	-----

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	12, 3R, 4x, 4, 13, 2
Additional condition protection degree	in closed state, inserted
<b>Device protection   Mechanical</b>	
Mechanical endurance	1,500 cycles
<b>Mechanical data   Mounting data</b>	
Depth	30 mm
Diameter	29.5 mm
Mounting depth	70 mm
Diameter cutout	22.5 mm
<b>Approvals</b>	
UL 50E	yes