


Modlight70 Pro LED modul blue

Input 24VDC
Art.No.: 4000-76070-1014000
Weight: 0.065 kg
Country of origin: ID
Model designation: Modlight70 Pro LED-B
LED module (blue)

Link to Product

Illustration

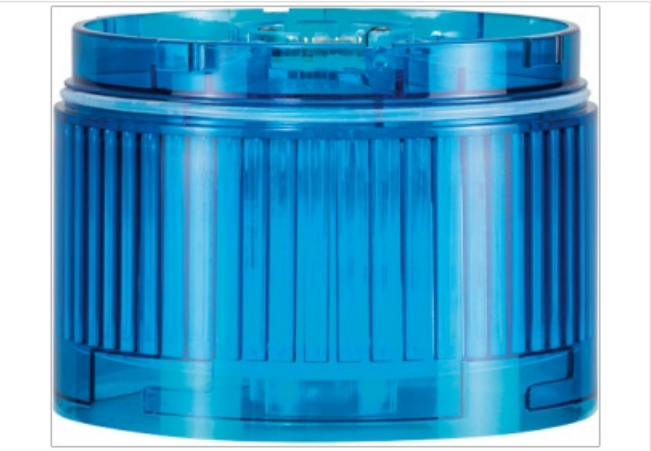

Product may differ from Image



Header	
Material short text	Modlight70 Pro LED-B
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-76070-1014000
GTIN	4048879752657
ECLASS-6.0	27371200
ECLASS-6.1	27371220
ECLASS-7.0	27371220
ECLASS-7.1	27371220
ECLASS-8.0	27371220
ECLASS-8.1	27371220
ECLASS-9.0	27371220
ECLASS-9.1	27371220
ECLASS-10.0.1	27371220
ECLASS-10.1	27371220
ECLASS-11.0	27371220
ECLASS-11.1	27371220
ECLASS-12.0	27371220
ECLASS-13.0	27371220
ECLASS-14.0	27371220
ETIM-5.0	EC000232

ETIM-6.0	EC000232
ETIM-7.0	EC000232
ETIM-8.0	EC000232
customs tariff number	85319000
EAN	4048879752657
Packaging unit	1
customs tariff number	85319000
EAN	4048879752657
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Current consumption max.	62,5 mA

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	locked, inserted

Mechanical data | Material data

Material housing	PC
------------------	----

Mechanical data | Mounting data

Height	49 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C