

Modlight70 Pro connecting modul 5 pole M12

downward, Input 24VDC

Art.No.: 4000-76070-1300010
Weight: 0.205 kg
Country of origin: CZ
Model designation: Modlight70 Pro BASE M12-5U


Basic
with M12 connection
Outlet on the bottom
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

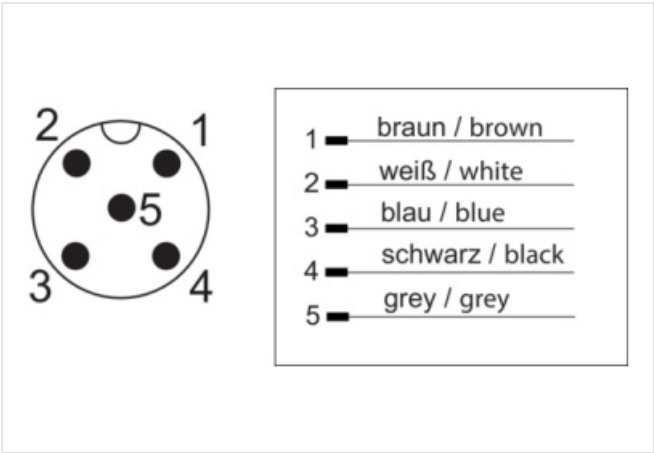

Header	
Material short text	Modlight70 Pro BASE M12-5U
Commercial data	
URL Webshop	https://shop.murrelektronik.com/4000-76070-1300010
GTIN	4048879758888
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-7.1	27371232
ECLASS-8.0	27371232
ECLASS-8.1	27371232
ECLASS-9.0	27371232
ECLASS-9.1	27371232
ECLASS-10.0.1	27371232
ECLASS-10.1	27371232
ECLASS-11.0	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232

ECLASS-13.0	27371232
ECLASS-14.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
ETIM-8.0	EC001152
customs tariff number	85319000
EAN	4048879758888
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	locked, inserted

Mechanical data | Material data

Material housing	Plastic
Color housing	Black

Mechanical data | Mounting data

Height	140 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C