

MVP12, 8XM12, MOSA, PLUG. CAP SCT.

With potent. sep.

Art.No.: 4927061

Weight: 0.249 kg

Country of origin: DE

Model designation: MVL8-V

pluggable connection cap

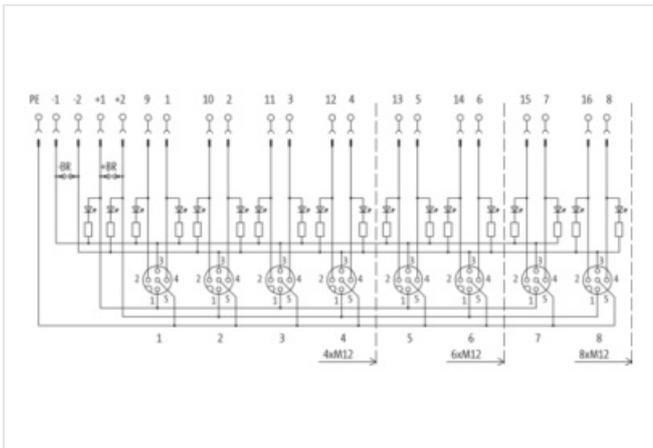
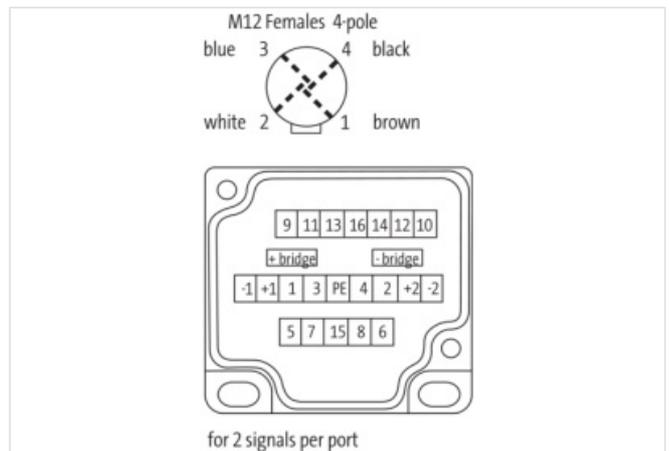
PIN 1: +24 V or PE selectable by plug links

Potential separation as option

with LED for digital PNP-signals 24 V DC

quick connection elements included

Further cable lengths on request.

Link to Product**Illustration**

Product may differ from Image

Header

Material short text

MVL8-V

Commercial data

URL Webshop

<https://shop.murrelektronik.com/4927061>

GTIN

4048879057646

ECLASS-6.0

27279219

ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879057646
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current at 1 time current feed-in max.	8 A
Total current at 2 times current feed-in max.	16 A

Industrial Communication

Number of signals per port	2
----------------------------	---

Installation

Connection cross section min.	0,25 mm ²
Connection cross section max.	0,5 mm ²

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	mounted, screwed

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Height	43 mm
Width	50,2 mm
Depth	170 mm
Mounting method	Cap nut

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Connection type 2

Family construction form	Cap
No. of poles	21
Family construction form	M12
No. of poles	4
Coding	HARAX

Gender	male
Color contact carrier	black
PIN 1	+ PE
PIN 2	NC
PIN 3	-
PIN 4	S