

SV-SUB D 37.-KL FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Art.No.: 54043

Weight: 0.100 kg

Country of origin: CZ

Model designation: SV-SUB D 37Bu.-KL



Female connector

37-pole

Screw terminals

[Link to Product](#)

Illustration

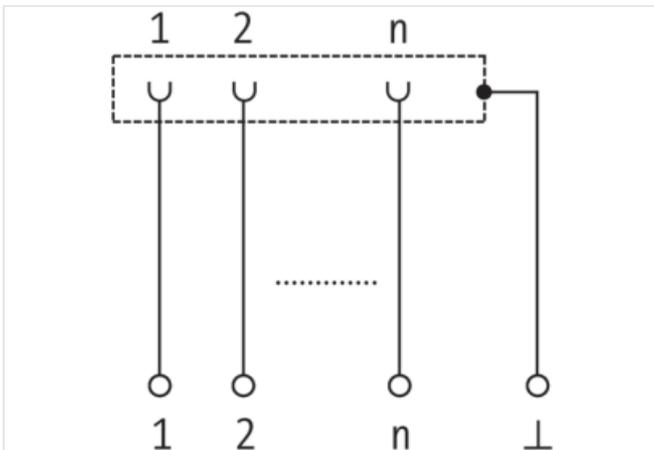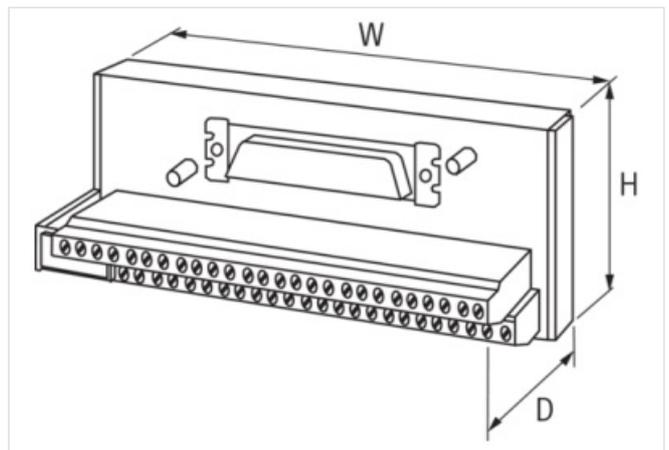

Product may differ from Image



Header

Material short text

SV-SUB D 37Bu.-KL

Commercial data

URL Webshop

<https://shop.murrelektronik.com/54043>

GTIN	4048879026468
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-7.1	27141152
ECLASS-8.0	27141152
ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85366990
EAN	4048879026468
Packaging unit	1

Electrical data | Supply

Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A

Device protection | Electrical

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

Mechanical data | Mounting data

Height	63 mm
Width	75 mm
Depth	58 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C