

## SV-SUB D 50.-KL FOR SIGNAL TRANSFER

to be discontinued - Last Time Order: 2023-03-31

Art.No.: 54044

Weight: 0.222 kg

Country of origin: CZ

Model designation: SV-SUB D 50Bu.-KL



Female connector

50-pole

Screw terminals

### [Link to Product](#)

#### Illustration

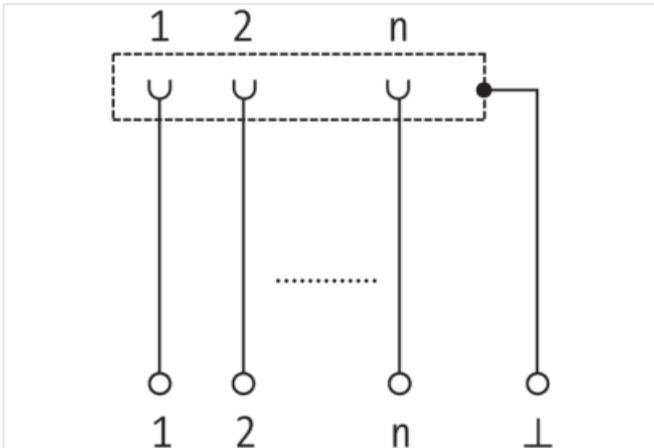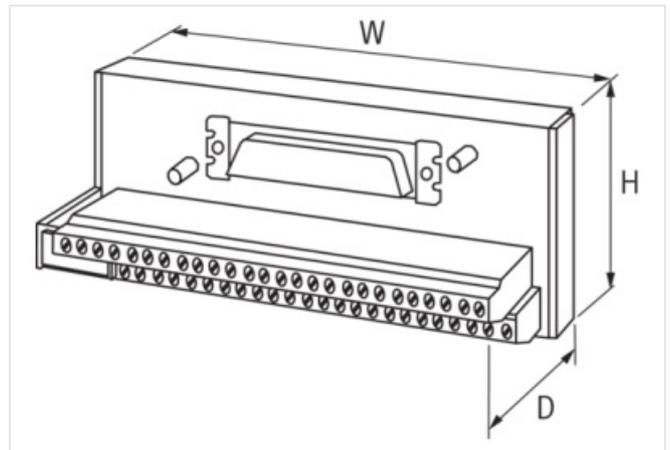

Product may differ from Image



#### Header

Material short text

SV-SUB D 50Bu.-KL

#### Commercial data

URL Webshop

<https://shop.murrelektronik.com/54044>

GTIN	4048879026451
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-7.1	27141152
ECLASS-8.0	27141152
ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85366990
EAN	4048879026451
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A

**Device protection | Electrical**

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

**Mechanical data | Mounting data**

Height	63 mm
Width	95 mm
Depth	58 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C