

LUGS 32 FOR SIGNAL TRANSFER

250V / 8 A

Art.No.: 54103

Weight: 0.216 kg

Country of origin: CZ



Model designation: LUGS 32

32-pole

Screw plug-in terminals

[Link to Product](#)

Illustration

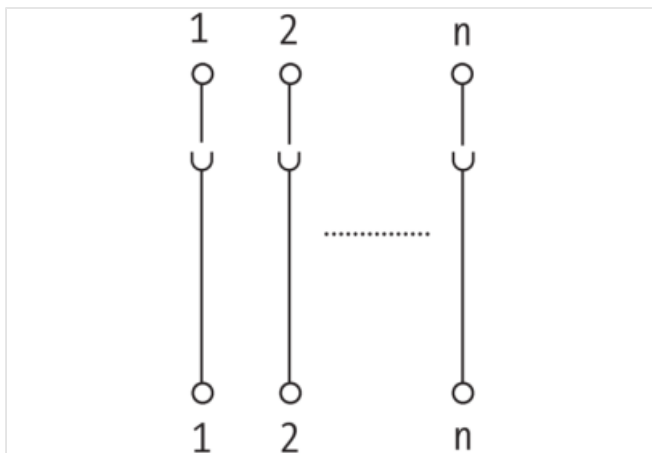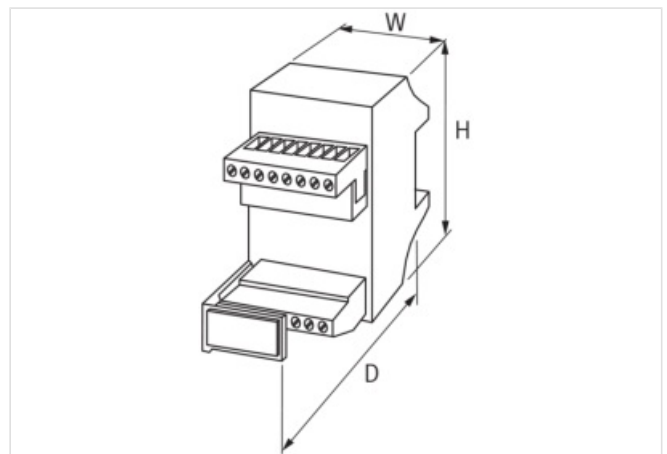

Product may differ from Image

Header

Material short text LUGS 32

Commercial data

URL Webshop	https://shop.murrelektronik.com/54103
GTIN	4048879026260
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-7.1	27141152
ECLASS-8.0	27141152

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-01-26

Murrelektronik GmbH | Grabenstraße 29 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

ECLASS-8.1	27141152
ECLASS-9.0	27141152
ECLASS-9.1	27141152
ECLASS-10.0.1	27141152
ECLASS-10.1	27141152
ECLASS-11.0	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ECLASS-13.0	27141152
ECLASS-14.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85369010
EAN	4048879026260
Packaging unit	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current max.	8 A

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Mechanical data | Mounting data

Height	75 mm
Width	90 mm
Depth	66 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C