

Adaptor M12 Male / M12 Female

Buffer module for DO (Pin 4-3)

Art.No.: 55112

Weight: 0.045 kg

Country of origin: DE

Model designation: M12/M12 Cap DO(4-3) 24VDC 11µF

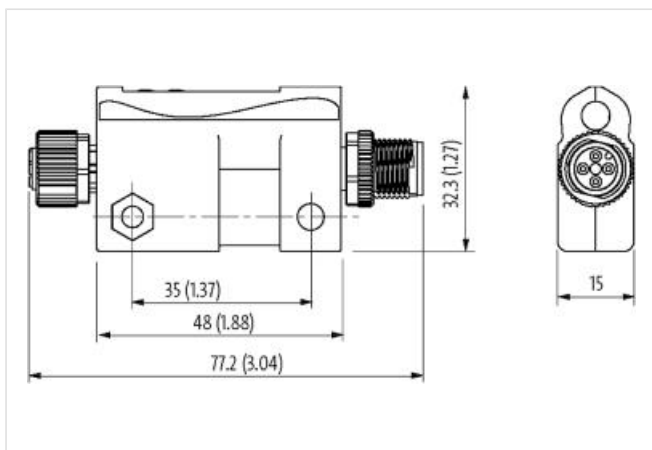
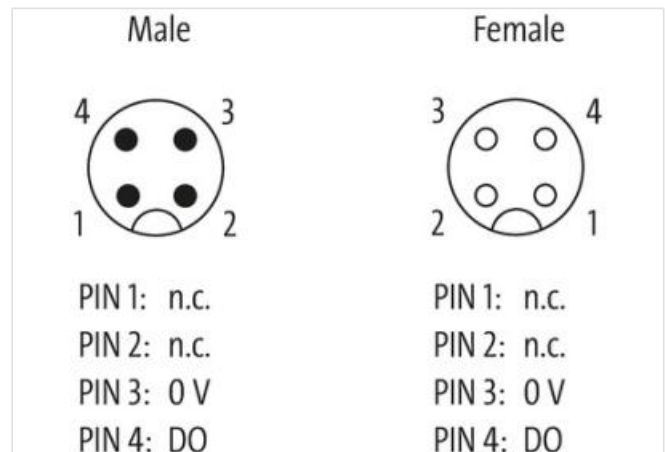
Adapter

Male - female

M12 – M12, 4-pole

max. 2 A

11 µF

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0

27143423

ECLASS-6.1	27260702
ECLASS-7.0	27440102
ECLASS-8.0	27440102
ECLASS-9.0	27440102
ECLASS-10.1	27440102
ECLASS-11.1	27440102
ECLASS-12.0	27440106
ETIM-5.0	EC001855
customs tariff number	85322400
customs tariff number	85322400
EAN	4048879713481
EAN	4048879713481
Packaging unit	1
Packaging unit	1

Electrical data

Electrical capacity max.	11 µF
--------------------------	-------

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	18 V
Operating voltage DC max.	30,2 V
Total current max.	2 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	screwed, mounted

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C
Relative humidity max. (operation)	85 %

Conformity

Product standard	EN 61131-2
------------------	------------