

CUBE67 ACCESSORIES

System interface connector

Art.No.: 56948

Weight: 0.150 kg

Country of origin: DE

Model designation: Cube67 FSC Socket M12 Mount

M12

Female straight

Internal system connection

with mounting socket


Flange, hole spacing 30 mm, bore 3.3 mm

Link to Product

Illustration



Product may differ from Image

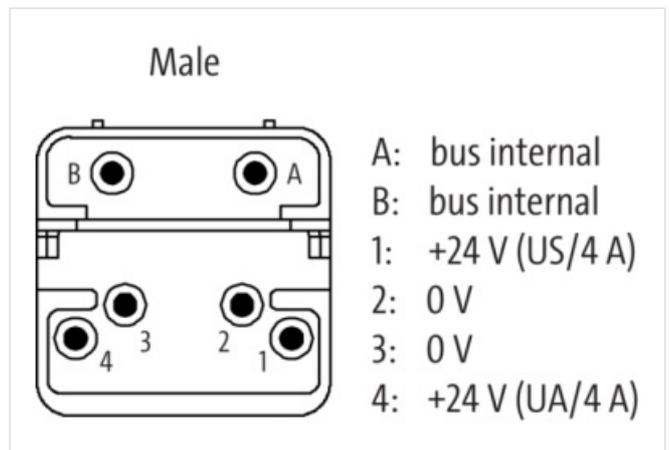

Header

Material short text Cube67 FSC Socket M12 Mount

Commercial data

URL Webshop	https://shop.murrelektronik.com/56948
GTIN	4048879047890
ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-7.1	27242692
ECLASS-8.0	27242692
ECLASS-8.1	27242692
ECLASS-9.0	27242692
ECLASS-9.1	27242692
ECLASS-10.0.1	27242692
ECLASS-10.1	27242692
ECLASS-11.0	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ECLASS-13.0	27242692
ECLASS-14.0	27242692
ETIM-5.0	EC001583
ETIM-6.0	EC001583

ETIM-7.0	EC001583
ETIM-8.0	EC001583
customs tariff number	85366990
EAN	4048879047890
Packaging unit	1

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	85 °C