

RS232


Art.No.: 57140
Weight: 0.060 kg
Country of origin: TH
Model designation: Cube20S Communication module RS232

RS232

Illustration



Product may differ from Image

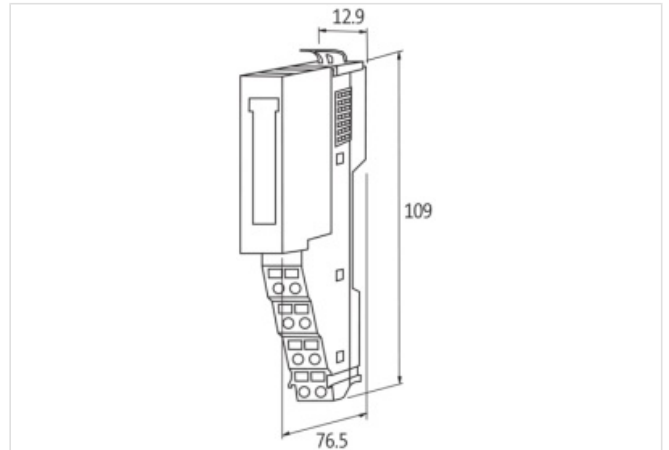

Material short text Cube20S Communication module RS232

URL Webshop	https://shop.murrelektronik.com/57140
GTIN	4048879422901
ECLASS-6.0	27242605
ECLASS-6.1	27242608
ECLASS-7.0	27242608
ECLASS-7.1	27242608
ECLASS-8.0	27242608
ECLASS-8.1	27242608
ECLASS-9.0	27242608
ECLASS-9.1	27242608
ECLASS-10.0.1	27242608
ECLASS-10.1	27242608
ECLASS-11.0	27242608
ECLASS-11.1	27242608
ECLASS-12.0	27242608
ECLASS-13.0	27242608
ECLASS-14.0	27242608
ETIM-5.0	EC001604

The information in this Product-PDF has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-21

ETIM-6.0	EC001604
ETIM-7.0	EC001604
ETIM-8.0	EC001604
customs tariff number	85389099
EAN	4048879422901
Packaging unit	1
Electrical data Supply	
Current consumption max.	100 mA
module supply	via system connection
Industrial Communication	
Transmission rate min.	150 kbit/s
Data transmission rate max.	115,2 kbit/s
Diagnostics	
Short circuit diagnosis	Yes
Overload diagnosis	Yes
Diagnostic	Under voltage
Diagnostic via BUS	per module
Diagnostic via LED	per module and channel
LED display	Ethernet connection/data traffic
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Mounting data	
Height	109 mm
Width	12,9 mm
Depth	76,5 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	60 °C
Ambient temperature (storage, transport)	-25 °C ... 70 °C
Connection type 2	
Connection type 1	Power
Connection type 2	Power
Family construction form	terminal
No. of poles	8
Gender	female
Connection	Spring clamp terminals FK
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys
Family construction form	terminal
No. of poles	8
Gender	female
Connection	Spring clamp terminals FK
PIN 1	TXD

PIN 2	RTS
PIN 3	DCD
PIN 4	DSR
PIN 5	RXD
PIN 6	CTS
PIN 7	GND_ISO
PIN 8	DTR