

ASSEMBLY MODULE MP 6 S



to be discontinued - Last Time Order: 2023-03-31

Art.No.: 62030
Weight: 0.104 kg
Country of origin: CZ
Model designation: MP 6 S

6 pairs of solder pins
screw terminals connected to solder pin pairs

Link to Product

Illustration

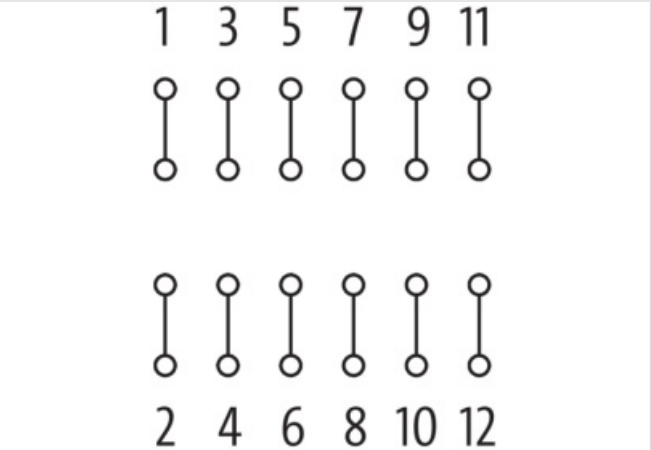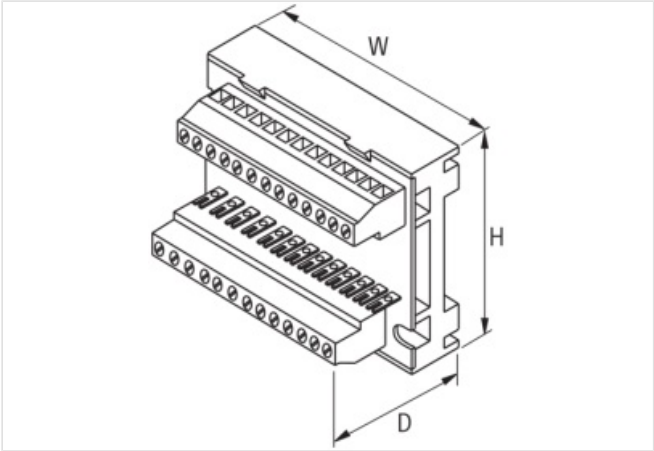

Product may differ from Image

Header	
Material short text	MP 6 S
Commercial data	
URL Webshop	https://shop.murrelektronik.com/62030
GTIN	4048879042239
ECLASS-6.0	27260710
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-7.1	27141149
ECLASS-8.0	27141149

ECLASS-8.1	27141149
ECLASS-9.0	27141149
ECLASS-9.1	27141149
ECLASS-10.0.1	27141149
ECLASS-10.1	27141149
ECLASS-11.0	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85369010
EAN	4048879042239
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	5 A

Installation

Connection cross section max.	4 mm ²
-------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
Connection information	Lötstützpunktpaare (Raster 5 mm)

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Housing properties	open design

Mechanical data | Mounting data

Height	63 mm
Width	90 mm
Depth	36 mm
Mounting method	geschnappt, screwed
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32
Distance of solder pins	50 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C