

MKS-D 10/1300-1 P DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67045

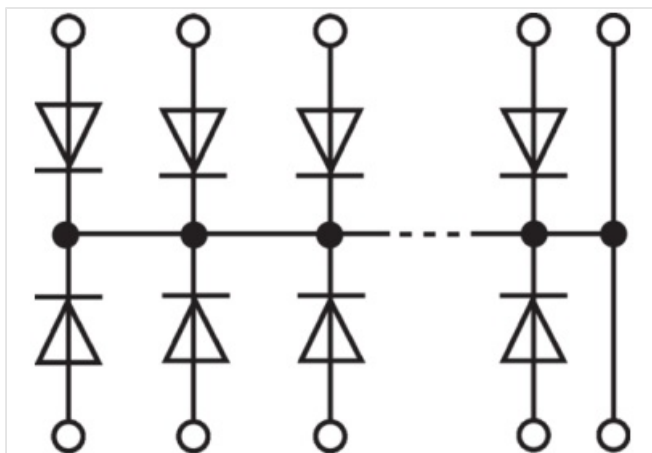
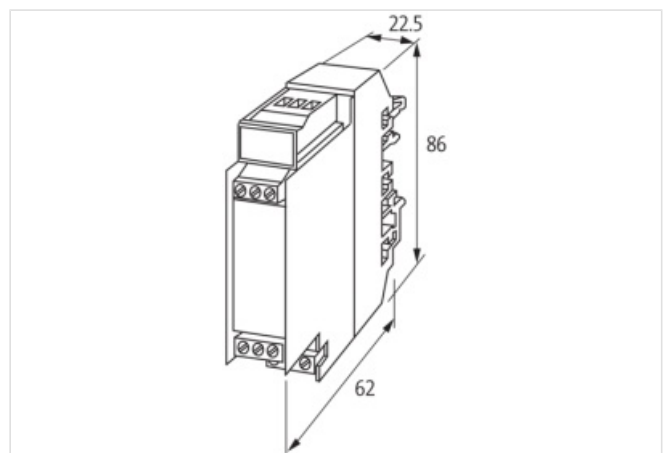
Weight: 0.068 kg

Country of origin: CZ

Model designation: MKS - D 10/1300-1 P

10 diodes

Common potential cathode

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text

MKS - D 10/1300-1 P

Commercial data

URL Webshop

<https://shop.murrelektronik.com/67045>

GTIN

4048879041935

ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-7.1	27371010
ECLASS-8.0	27371010
ECLASS-8.1	27371010
ECLASS-9.0	27371010
ECLASS-9.1	27371010
ECLASS-10.0.1	27371010
ECLASS-10.1	27371010
ECLASS-11.0	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010
ECLASS-13.0	27371010
ECLASS-14.0	27371010
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85411000
EAN	4048879041935
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	48 V
Operating voltage DC max.	48 V

Mechanical data | Mounting data

Height	86 mm
Width	22,5 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	terminal
No. of poles	12
Gender	female
Connection	Screw terminals SK