

MKS - D 6/1300 - 1 DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67063

Weight: 0.066 kg

Country of origin: CZ

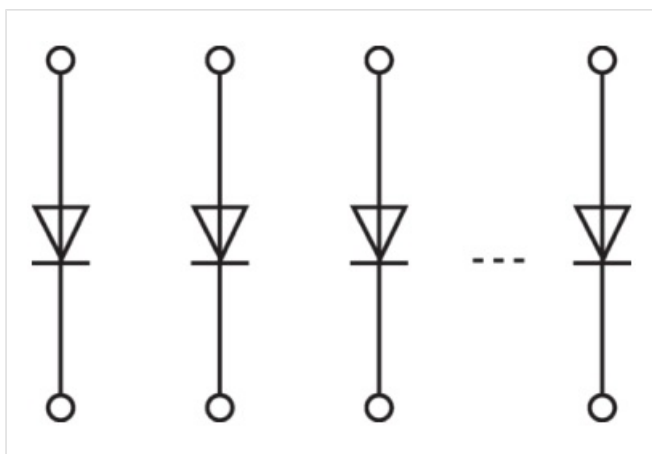
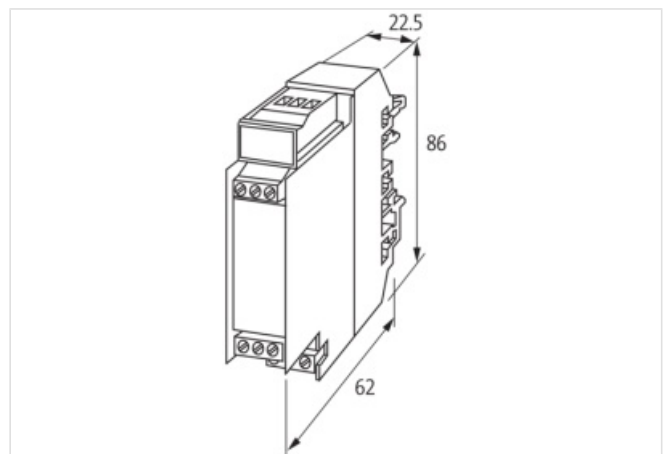
Model designation: MKS - D 6/1300-1

Universal diode 1 300 V, 1 A

6 diodes

separation contact via pluggable jumpers

Diode modules are suitable for the suppression of inductive loads (valve, contactor, etc.)

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

MKS - D 6/1300-1

Commercial data

URL Webshop	https://shop.murrelektronik.com/67063
GTIN	4048879041904
ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-7.1	27371010
ECLASS-8.0	27371010
ECLASS-8.1	27371010
ECLASS-9.0	27371010
ECLASS-9.1	27371010
ECLASS-10.0.1	27371010
ECLASS-10.1	27371010
ECLASS-11.0	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010
ECLASS-13.0	27371010
ECLASS-14.0	27371010
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85411000
EAN	4048879041904
Packaging unit	1

Electrical data | Supply

Operating voltage AC max.	48 V
Operating voltage DC max.	48 V

Mechanical data | Mounting data

Height	86 mm
Width	22,5 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	terminal
No. of poles	12
Gender	female
Connection	Screw terminals SK