

MKS-LDP 5/1300 - 1 M DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67072

Weight: 0.067 kg

Country of origin: CZ

Model designation: MKS-LDP 5/1300-1 M

Universal diode 1 300 V, 1 A



5 pair of diodes

Common potential anode

Pairs of joined diodes with common control for lamp test

[Link to Product](#)

Illustration

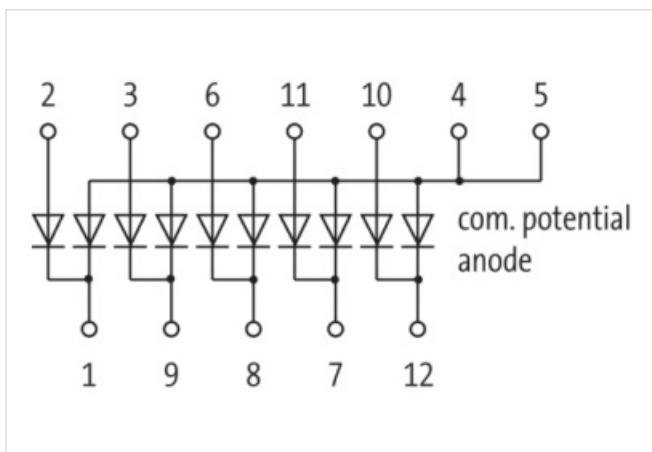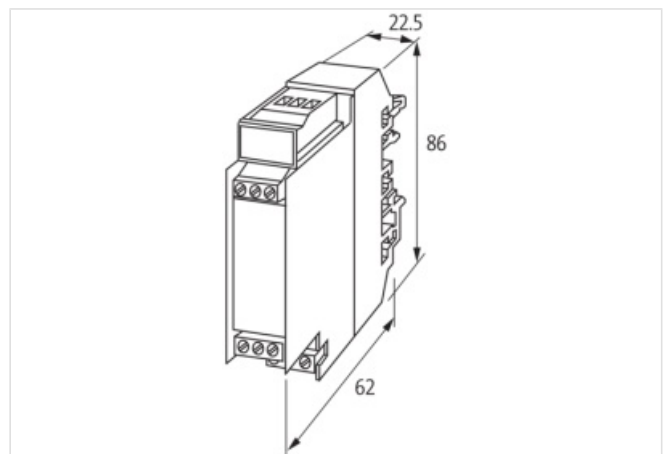

Product may differ from Image



Header

Material short text

MKS-LDP 5/1300-1 M

Commercial data

URL Webshop	https://shop.murrelektronik.com/67072
GTIN	4048879041843
ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-7.1	27371010
ECLASS-8.0	27371010
ECLASS-8.1	27371010
ECLASS-9.0	27371010
ECLASS-9.1	27371010
ECLASS-10.0.1	27371010
ECLASS-10.1	27371010
ECLASS-11.0	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010
ECLASS-13.0	27371010
ECLASS-14.0	27371010
ETIM-5.0	EC002780
ETIM-6.0	EC002780
ETIM-7.0	EC002780
ETIM-8.0	EC002780
customs tariff number	85411000
EAN	4048879041843
Packaging unit	1

Mechanical data | Mounting data

Height	86 mm
Width	22,5 mm
Depth	62 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715), G32

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	terminal
No. of poles	12
Gender	female
Connection	Screw terminals SK