

## MKS/BCD-1300 DIODE MODULES

Mounting rail / screw-type terminal

Art.No.: 67079

Weight: 0.131 kg

Country of origin: CZ



Model designation: MKS/BCD-1300

Universal diode 1 300 V, 1 A

Diode logic for converting hexadecimal to binary numbers

### [Link to Product](#)

#### Illustration

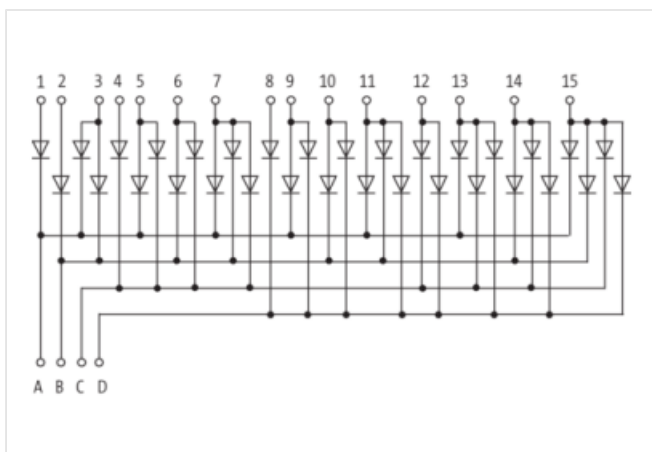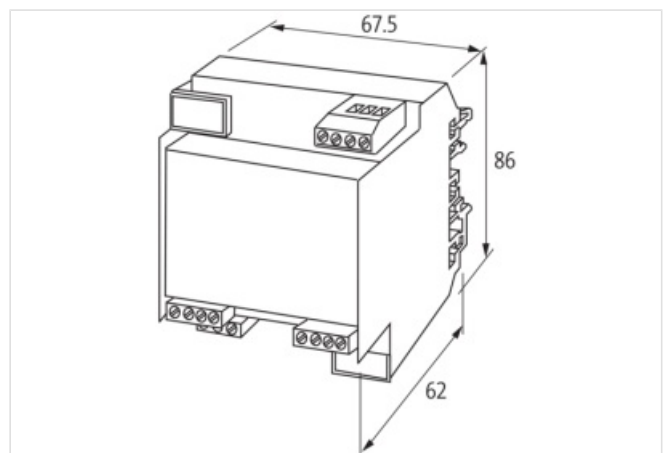

Product may differ from Image



#### Header

Material short text MKS/BCD-1300

#### Commercial data

URL Webshop <https://shop.murrelektronik.com/67079>

GTIN 4048879041829

|                       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27371010      |
| ECLASS-6.1            | 27371010      |
| ECLASS-7.0            | 27371010      |
| ECLASS-7.1            | 27371010      |
| ECLASS-8.0            | 27371010      |
| ECLASS-8.1            | 27371010      |
| ECLASS-9.0            | 27371010      |
| ECLASS-9.1            | 27371010      |
| ECLASS-10.0.1         | 27371010      |
| ECLASS-10.1           | 27371010      |
| ECLASS-11.0           | 27371010      |
| ECLASS-11.1           | 27371010      |
| ECLASS-12.0           | 27371010      |
| ECLASS-13.0           | 27371010      |
| ECLASS-14.0           | 27371010      |
| ETIM-5.0              | EC002780      |
| ETIM-6.0              | EC002780      |
| ETIM-7.0              | EC002780      |
| ETIM-8.0              | EC002780      |
| customs tariff number | 85411000      |
| EAN                   | 4048879041829 |
| Packaging unit        | 1             |

**Mechanical data | Mounting data**

|                            |                                     |
|----------------------------|-------------------------------------|
| Height                     | 86 mm                               |
| Width                      | 67,5 mm                             |
| Depth                      | 62 mm                               |
| Mounting method            | geschnappt                          |
| Suitable for mounting type | Mounting rail TH35, (EN 60715), G32 |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |

**Connection type 2**

|                          |                    |
|--------------------------|--------------------|
| Family construction form | terminal           |
| No. of poles             | 4                  |
| Gender                   | female             |
| Connection               | Screw terminals SK |
| PIN 1                    | D                  |
| PIN 2                    | C                  |
| PIN 3                    | B                  |
| PIN 4                    | A                  |
| Family construction form | terminal           |
| No. of poles             | 15                 |
| Gender                   | female             |
| Connection               | Screw terminals SK |