

MSVD POWER SOCKET NEMA WITH LED

Mounting rail
Art.No.: 676152
Weight: 0.159 kg
Country of origin: CZ
Model designation: MSVD BRASIL.STECKDOSE SCHNAPP.


USA (NEMA 5-15)
Connection turned
Screw terminals
LED (yellow)

Link to Product

Illustration



Product may differ from Image

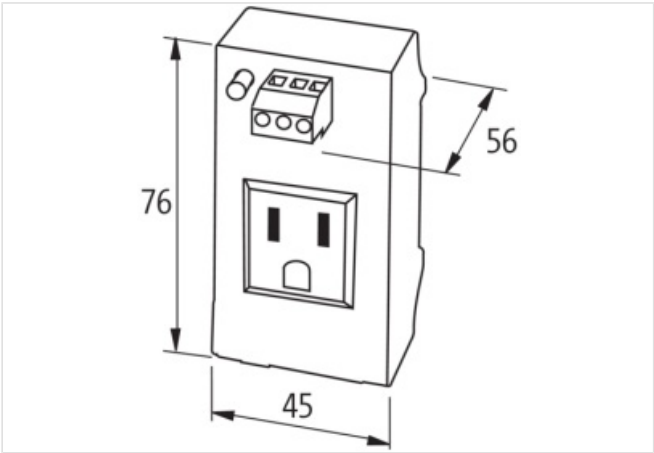

Header	
Material short text	MSVD BRASIL.STECKDOSE SCHNAPP.
Commercial data	
URL Webshop	https://shop.murrelektronik.com/676152
GTIN	4048879039680
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-7.1	27142305
ECLASS-8.0	27142305
ECLASS-8.1	27142305
ECLASS-9.0	27142305
ECLASS-9.1	27142305
ECLASS-10.0.1	27142305
ECLASS-10.1	27142305
ECLASS-11.0	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305

ECLASS-13.0	27142305
ECLASS-14.0	27142305
ETIM-5.0	EC000020
ETIM-6.0	EC000020
ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
EAN	4048879039680
Packaging unit	1

Electrical data | Supply

Operating voltage AC	127 V
Operating current	15 A

Installation

Connection cross section max.	2,5 mm ²
AWG number	14

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	56 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail