

MSVD POWER SOCKET NEMA (GFCI)

Mounting rail

Art.No.: 67981
Weight: 0.210 kg
Country of origin: CZ
Model designation: MSVD 2-fach NEMA 5-20R (GFCI)

USA (2× NEMA-GFCI 5-20)
(Ground Fault Circuit Interrupter)
Screw terminals


Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Link to Product

Illustration



Product may differ from Image

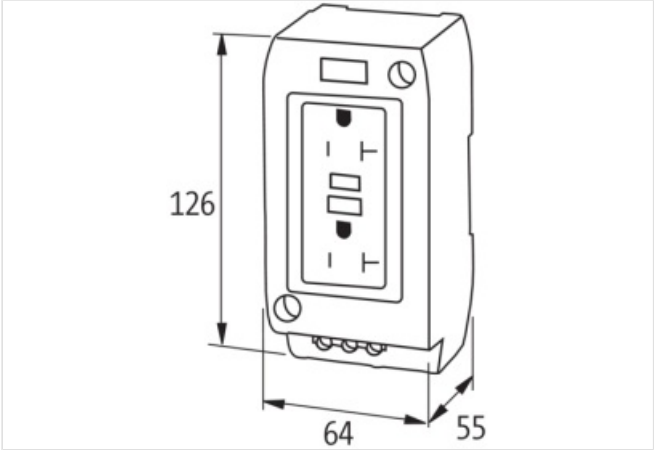

Header	
Material short text	MSVD 2-fach NEMA 5-20R (GFCI)
Commercial data	
URL Webshop	https://shop.murrelektronik.com/67981
GTIN	4048879041386
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-7.1	27142305
ECLASS-8.0	27142305
ECLASS-8.1	27142305
ECLASS-9.0	27142305
ECLASS-9.1	27142305
ECLASS-10.0.1	27142305
ECLASS-10.1	27142305
ECLASS-11.0	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305

ECLASS-13.0	27142305
ECLASS-14.0	27142305
ETIM-5.0	EC000020
ETIM-6.0	EC000020
ETIM-7.0	EC000020
ETIM-8.0	EC000020
customs tariff number	85366990
EAN	4048879041386
Packaging unit	1

Electrical data

Fault current min.	4 mA
Fault current max.	6 mA

Electrical data | Supply

Power frequency	60 Hz
Operating voltage AC	125 V
Operating current max.	20 A

Installation

Connection cross section max.	6 mm ²
-------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Mechanical data | Mounting data

Height	126 mm
Width	64 mm
Depth	55 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail