

**M12 MALE 0° CODING PLUG JUMPER 1-4**

Art.No.: 7000-13483-0000000

Weight: 0.009 kg

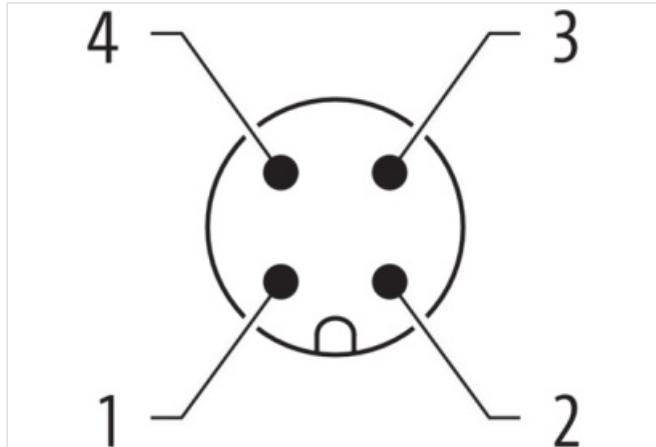
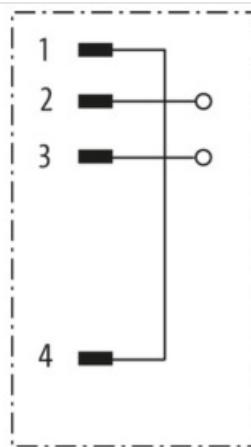
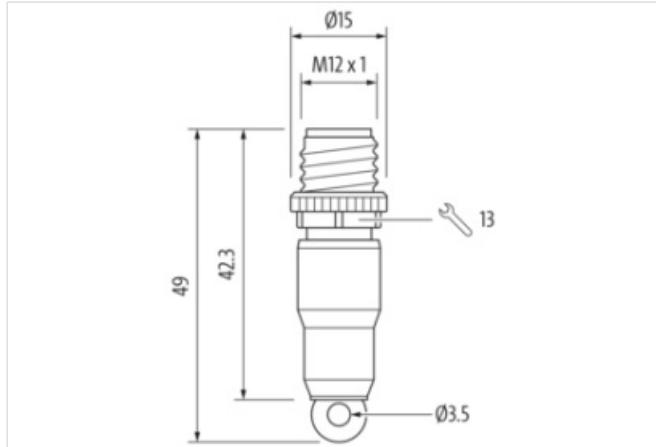
Country of origin: DE

Model designation: MSA05L0-X 1-4

Terminating plug

Male M12

4-pole (bridged)

[Link to Product](#)
**Illustration**


Product may differ from Image

**Side 1**

Family construction form	M12
No. of poles	4
Coding	A
Mounting method	inserted, screwed
Width across flats	SW13
Degree of protection (EN IEC 60529)	IP67

**Commercial data**

URL Webshop	<a href="https://shop.murrelektronik.com/7000-13483-0000000">https://shop.murrelektronik.com/7000-13483-0000000</a>
customs tariff number	85366990

EAN	4048879714303
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Current operating per contact max.	4 A

**Installation | Connection**

Tightening torque	0.6 Nm
-------------------	--------

**Device protection | Electrical**

Additional condition protection degree	inserted, screwed
Pollution Degree	3
Rated surge voltage	0.8 kV
Material group (IEC 60664-1)	I

**Mechanical data | Material data**

Locking material	Zinc die-casting
Coating locking	Nickel

**Mechanical data | Mounting data**

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-30 °C
Operating temperature max.	85 °C

**Conformity**

Product standard	EN IEC 61076-2-101 (M12)
------------------	--------------------------