

**Adaptor M12 male / M12 female A-cod. shielded**

5-pol. / 4-pol., for analog sensors

Art.No.: 7000-42261-0000000

Weight: 0.015 kg

Country of origin: DE




Model designation: MSB04L0-A-I-ZE 3-4




Adapter

Male - female

M12 – M12, 5-pole

Shielded

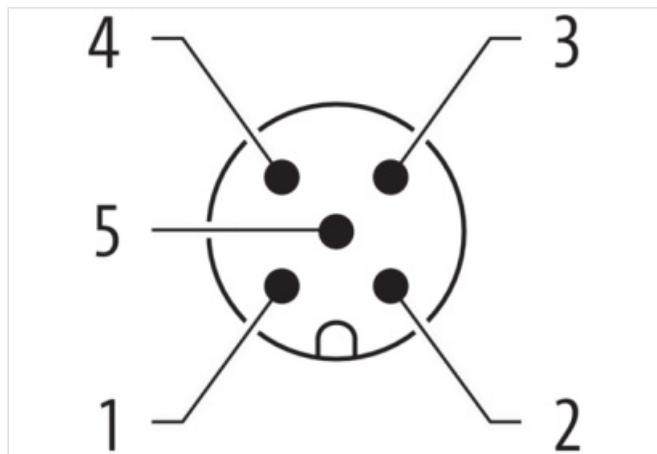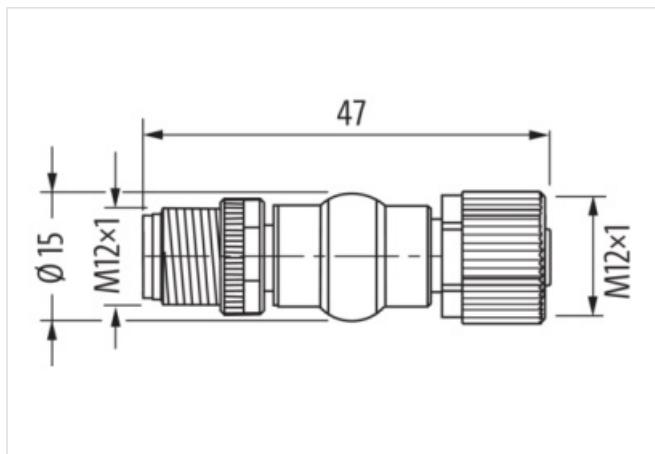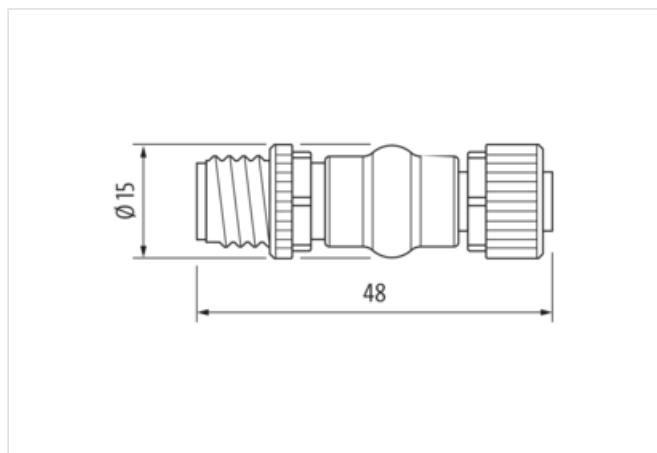[Link to Product](#)Illustration

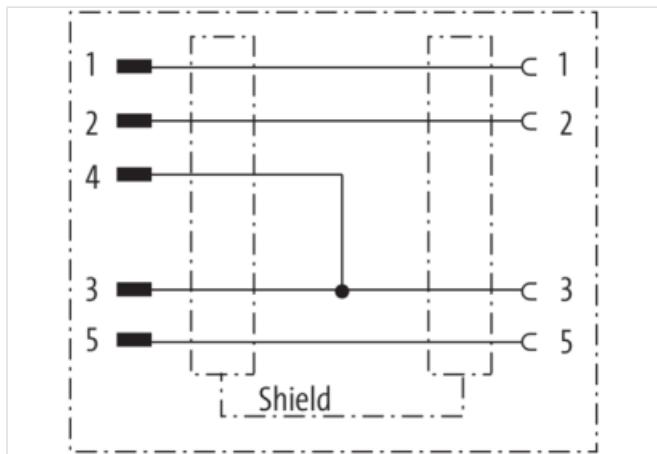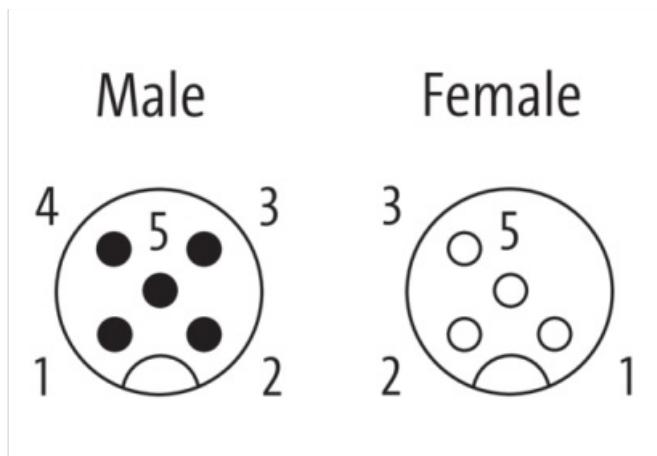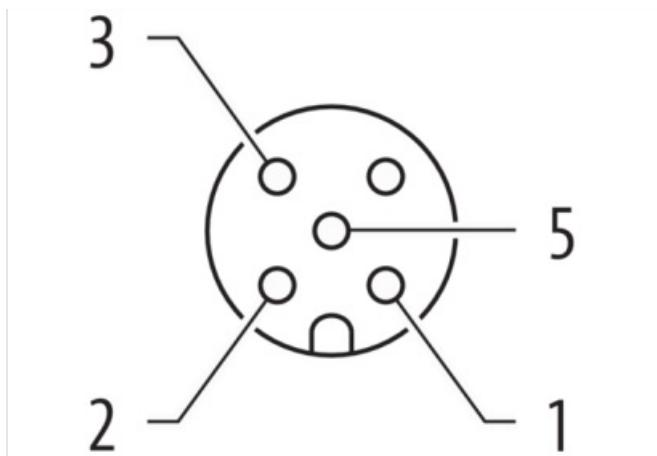

Product may differ from Image



#### Commercial data

URL Webshop	<a href="https://shop.murrelektronik.com/7000-42261-0000000">https://shop.murrelektronik.com/7000-42261-0000000</a>
customs tariff number	85366990
EAN	4048879332927
Packaging unit	1

#### Electrical data | Supply

Operating voltage AC max.	60 V
Operating voltage DC max.	60 V
Current operating per contact max.	4 A
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	30 V

#### Installation | Connection

Tightening torque	0,6 Nm
Mounting set	M12 x 1

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed

Rated insulation voltage 800 V

**Mechanical data | Material data**

Material housing	PUR
Locking material	Zinc die-casting
Coating locking	Nickelated

**Mechanical data | Mounting data**

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-30 °C
Operating temperature max.	85 °C

**Important installation notes**

Note on bending radius	<b>Attention:</b> Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.