

CABLE GLAND PA M12X 1.5

Art.No.: 7000-91001-0001200
Weight: 0.003 kg
Country of origin: DE
Model designation: Kabelverschraubung PA M12X1,5


Cable compression gland
metric
M12×1.5 mm
(gray)
(conduit on request)
Quantity: 100 pcs.

Link to Product

Illustration



Product may differ from Image

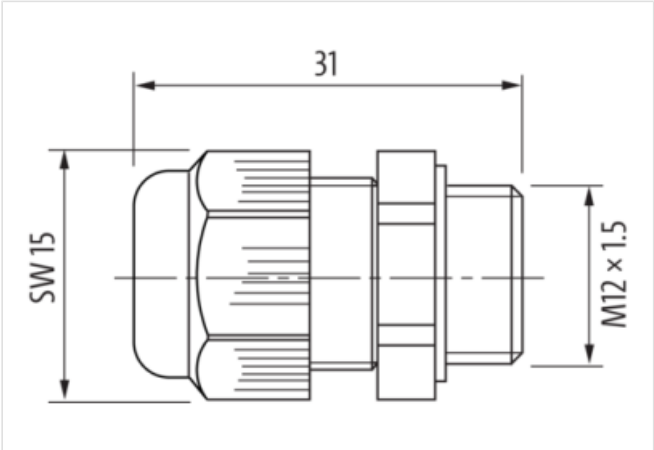

Header

Material short text Kabelverschraubung PA M12X1,5

Commercial data

URL Webshop	https://shop.murrelektronik.com/7000-91001-0001200
GTIN	4048879468237
ECLASS-6.0	27279221
ECLASS-6.1	27149109
ECLASS-7.0	27149109
ECLASS-7.1	27149109
ECLASS-8.0	27149109
ECLASS-8.1	27149109
ECLASS-9.0	27140801
ECLASS-9.1	27144432
ECLASS-10.0.1	27144432
ECLASS-10.1	27144432
ECLASS-11.0	27144432
ECLASS-11.1	27144432
ECLASS-12.0	27140801
ECLASS-13.0	27140801
ECLASS-14.0	27140801
ETIM-5.0	EC001855
ETIM-6.0	EC001855

ETIM-7.0	EC001855
ETIM-8.0	EC001855
customs tariff number	39174000
EAN	4048879468237
Packaging unit	100
customs tariff number	39174000
EAN	4048879468237
Packaging unit	100

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP68
Additional condition protection degree	mounted, screwed

Mechanical data | Material data

Material housing	PA6
Material gasket	NBR

Mechanical data | Mounting data

Height	31 mm
Width	15 mm
Depth	15 mm
Clamping range min.	3 mm
Clamping range max.	6 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	100 °C
Additional condition temperature range	depending on cable quality