

CABLE GLAND PA M16X 1.5

Art.No.: 7000-91001-0001600

Weight: 0.006 kg

Country of origin: DE

Model designation: Kabelverschraubung PA M16X1,5

Cable compression gland

M16 x 1.5

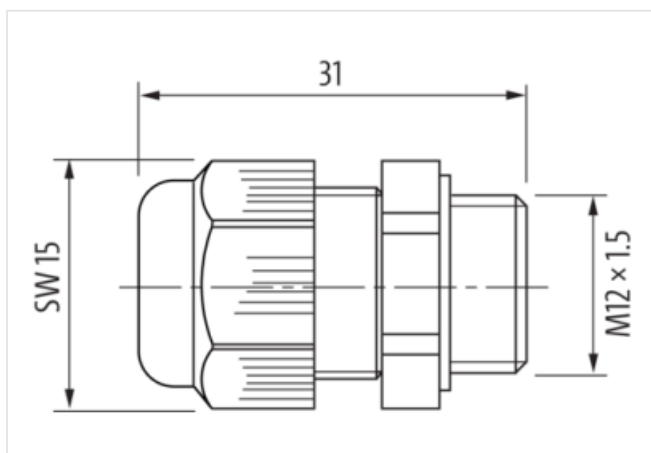
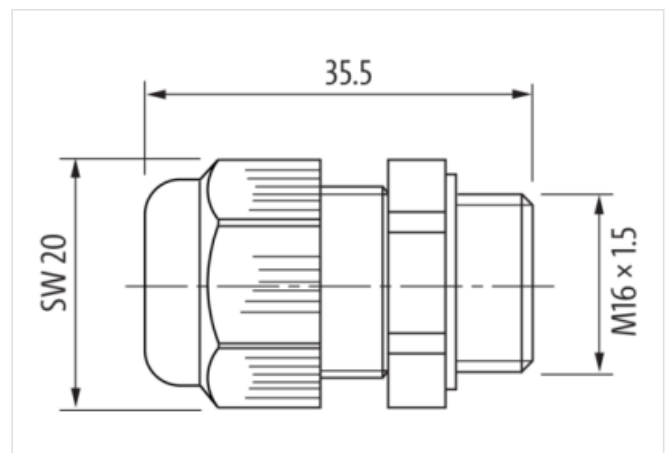
metric

(gray)

2x pin connector 26pol gray

(conduit on request)

Quantity: 100 pcs.

[Link to Product](#)**Illustration**

Product may differ from Image

Header

Material short text

Kabelverschraubung PA M16X1,5

Commercial data

URL Webshop	https://shop.murrelektronik.com/7000-91001-0001600
GTIN	4048879468251
ECLASS-6.0	27279221
ECLASS-6.1	27149109

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-03

Murrelektronik GmbH | Grabenstraße 29 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

ECLASS-7.0	27149109
ECLASS-7.1	27149109
ECLASS-8.0	27149109
ECLASS-8.1	27149109
ECLASS-9.0	27140801
ECLASS-9.1	27144432
ECLASS-10.0.1	27144432
ECLASS-10.1	27144432
ECLASS-11.0	27144432
ECLASS-11.1	27144432
ECLASS-12.0	27140801
ECLASS-13.0	27140801
ECLASS-14.0	27140801
ETIM-5.0	EC001855
ETIM-6.0	EC001855
ETIM-7.0	EC001855
ETIM-8.0	EC001855
customs tariff number	39174000
EAN	4048879468251
Packaging unit	100
customs tariff number	39174000
EAN	4048879468251
Packaging unit	100

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP68
-------------------------------------	------

Mechanical data | Material data

Material housing	PA
Material gasket	NBR

Mechanical data | Mounting data

Height	35,5 mm
Width	15 mm
Depth	15 mm
Clamping range min.	5 mm
Clamping range max.	10 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	100 °C
Additional condition temperature range	depending on cable quality