

MIRO 6.2 PLUGGABLE PLUG IN MODULE OUTPUT RELAY

IN: 24 VDC - OUT: 250 VAC/DC / 6 A

Art.No.: 3000-16023-2100010

Weight: 0.005 kg

Country of origin: CZ

Model designation: Ausgrel. 24V/230V 6A (Steckmodul)

Output relay

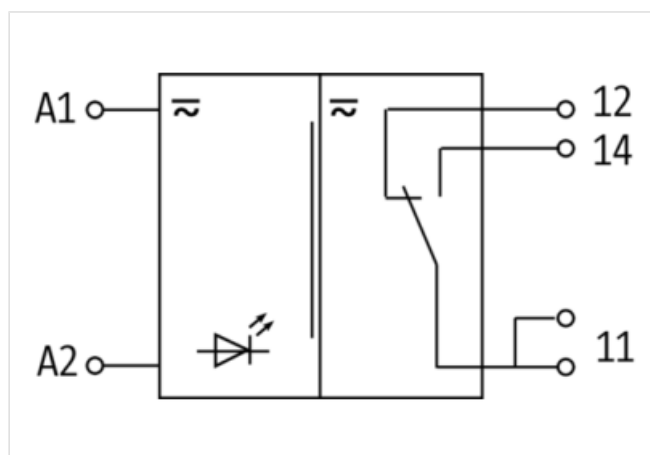
1 relay; 1 NO contact

24 V AC/DC

6 A

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/3000-16023-2100010
GTIN	4048879021371
EU-Customs tariff number	85364900
US-Customs tariff number	8536490080
ECLASS-6.0	27371601
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-7.1	27371601
ECLASS-8.0	27371601
ECLASS-8.1	27371601
ECLASS-9.0	27371601
ECLASS-9.1	27371601
ECLASS-10.0.1	27371601
ECLASS-10.1	27371601
ECLASS-11.0	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ECLASS-13.0	27371601

ECLASS-14.0	27371601
ETIM-5.0	EC001437
ETIM-6.0	EC001437
ETIM-7.0	EC001437
ETIM-8.0	EC001437
ETIM-9.0	EC001437
ETIM-10.0	EC001437
customs tariff number	85364900
EAN	4048879021371
Packaging unit	1

Electrical data | Input

Input voltage AC	24 V
Input voltage DC	24 V

Electrical data | Output

Switching voltage AC max.	250 V
Switching voltage DC max.	30 V
Switching current	6 A
Switching current DC	10 mA
Switching current DC min.	100 mA
Power rating AC max.	1.500 VA
Power rating DC max.	120 W

Device protection | Electrical

Rated insulation voltage	300 V
--------------------------	-------

Mechanical data

Response time max.	8 ms
Drop-out time max.	4 ms

Mechanical data | Material data

Material contact	Ag Sn O2
------------------	----------

Mechanical data | Mounting data

Mounting method	inserted
-----------------	----------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	60 °C
Ambient temperature (storage, transport)	-40 °C ... 60 °C