

Modlink MSDD-set: Frame 4000-68512-0000003,

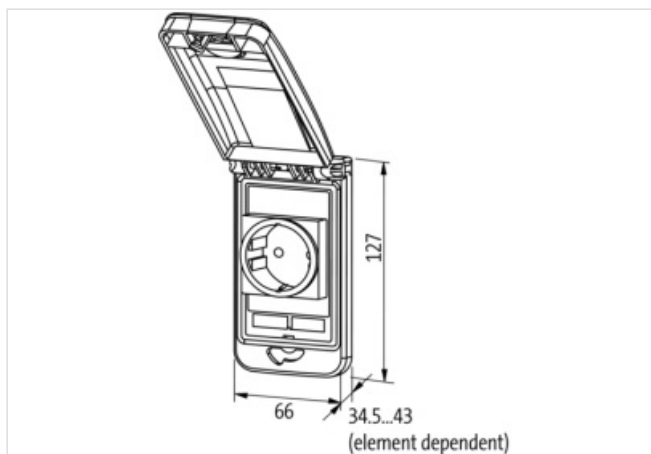
insert 4000-68000-0940000

Art.No.: 4000-68512-0940003

Weight: 0.188 kg

Country of origin: CZ

Model designation: MSDD_1transparent_USB+2XRJ45-BU/BU_

Link to Product**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/4000-68512-0940003
GTIN	4048879406741
EU-Customs tariff number	85366990
US-Customs tariff number	8536694020
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217

ECLASS-7.1	27189217
ECLASS-8.0	27189217
ECLASS-8.1	27189217
ECLASS-9.0	27182806
ECLASS-9.1	27189217
ECLASS-10.0.1	27182806
ECLASS-10.1	27182806
ECLASS-11.0	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ECLASS-13.0	27182806
ECLASS-14.0	27182806
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
ETIM-9.0	EC002625
ETIM-10.0	EC002625
customs tariff number	85366990
EAN	4048879406741
Packaging unit	1
Frame	
housing	PA
Color housing	black
Lid	PC
Color cover	transparent
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Shielding plate	
Connection information	Threaded hole M4
Tightening torque	0,9 Nm
Tightening torque tolerance	± 0,1 Nm
USB	
USB specification	3.0
Looking techniques	Snap-in connector
Data transmission rate max.	5.000 Mbit/s
Operating voltage AC	48 V
Operating voltage DC	48 V
Operating current	1,5 A
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
RJ45	
Family construction form	RJ45
Looking techniques	Snap-in connector
Cable category min.	Cat5e
Family type Back side	RJ45
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V

Current operating max. (UL)	175 mA
-----------------------------	--------