

CUBE20S SSI MODULE

SSI Encoder

Art.No.: 57142
Weight: 0.065 kg
Country of origin: TH
Model designation: Cube20S SSI module SSI Encoder


RS422

Link to Product

Illustration



Product may differ from Image

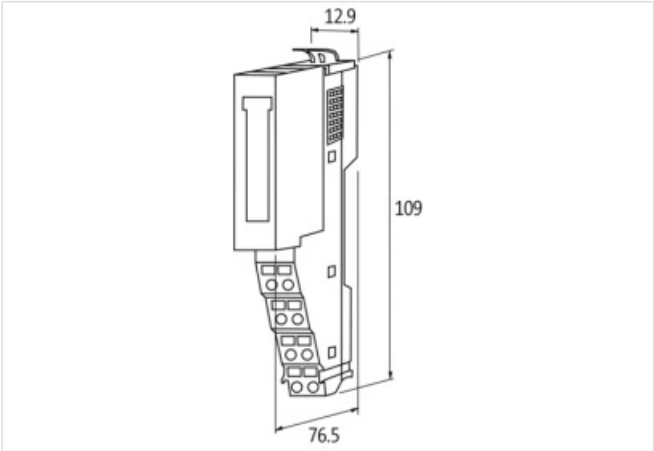

Commercial data

URL Webshop	https://shop.murrelektronik.com/57142
GTIN	4048879422925
EU-Customs tariff number	85389099
US-Customs tariff number	8538908180
ECLASS-6.0	27242605
ECLASS-7.0	27242605
ECLASS-8.0	27242605
ECLASS-9.0	27242605
ETIM-5.0	EC001601
ETIM-6.0	EC001601
ETIM-7.0	EC001601
ETIM-8.0	EC001601
ETIM-9.0	EC001601
ETIM-10.0	EC001601
customs tariff number	85389099
EAN	4048879422925
Packaging unit	1

Electrical data | Supply

Current consumption max.	70 mA
module supply	via system connection

Diagnostics

Short circuit diagnosis	Yes
Overload diagnosis	Yes
Diagnostic	Under voltage
Diagnostic via BUS	per module
Diagnostic via LED	per module and channel
LED display	Ethernet connection/data traffic

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Mounting data

Height	109 mm
Width	12,9 mm
Depth	76,5 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	60 °C
Ambient temperature (storage, transport)	-25 °C ... 70 °C

Connection type 2

Connection type 1	Power
Connection type 2	Power
Family construction form	terminal
No. of poles	8
Gender	female
Color contact carrier	black
Connection	Spring clamp terminals FK
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys
Family construction form	terminal
No. of poles	8
Gender	female
Connection	Spring clamp terminals FK
PIN 1	CO +
PIN 2	24 V DC
PIN 3	0 V
PIN 4	CI +
PIN 5	CO -
PIN 6	DI +
PIN 7	DI -
PIN 8	CI -