

MET 1-PHASE SAFETY TRANSFORMER

P: 500VA IN: 400VAC+/- 5% OUT: 24VAC

Art.No.: 86024

Weight: 7.650 kg

Country of origin: CZ

Model designation: MET 0500-400+-5%/24



Single-phase safety transformer

500 VA

Isolation class T 60/B

Link to Product

Illustration

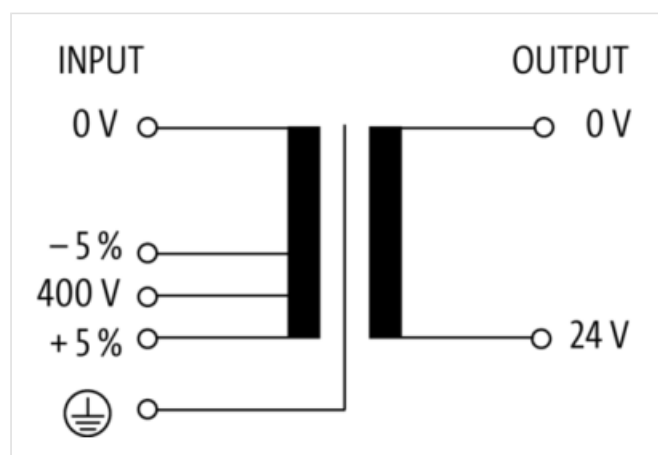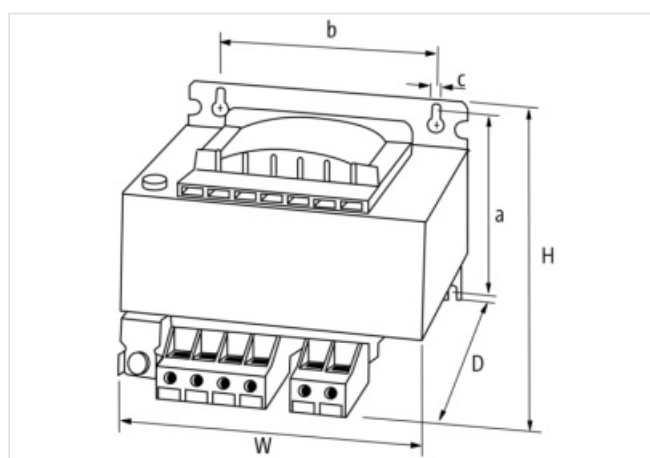

Product may differ from Image



Commercial data

URL Webshop	https://shop.murrelektronik.com/86024
GTIN	4048879079020
EU-Customs tariff number	85043180
US-Customs tariff number	8504314065

ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-7.1	27031302
ECLASS-8.0	27031302
ECLASS-8.1	27031302
ECLASS-9.0	27031302
ECLASS-9.1	27031302
ECLASS-10.0.1	27031302
ECLASS-10.1	27031302
ECLASS-11.0	27031302
ECLASS-11.1	27031302
ECLASS-12.0	27031302
ECLASS-13.0	27031302
ECLASS-14.0	27031302
ETIM-5.0	EC002486
ETIM-6.0	EC002486
ETIM-7.0	EC002486
ETIM-8.0	EC002486
ETIM-9.0	EC002486
ETIM-10.0	EC002486
customs tariff number	85043180
EAN	4048879079020
Packaging unit	1

Electrical data | Supply

Protective measure	SELV
Power frequency	50 ... 60 Hz

Electrical data | Input

Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Current input AC	2,67 A
Max. inrush current	20,76 A
Short-circuit current	43,13 A

Electrical data | Output

Output voltage adjustable	No
Output voltage AC	24 V
Power rating AC max.	500 VA

Device protection | Electrical

Insulation test voltage input - output	4 kV
--	------

Mechanical data | Mounting data

Height	112,6 mm
Width	150 mm
Depth	146 mm
Suitable for mounting type	Keyhole mounting
Mounting dimension a	91 mm
Mounting dimension b	122 mm
Mounting dimension c	7 mm
Diameter bore	7 mm
Length bore	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	60 °C
Ambient temperature (storage, transport)	-40 °C ... 80 °C

Conformity

Product standard	EN IEC 61558-2-4, EN IEC 61558-2-6, IEC 62041 category 0
------------------	--