

10016000	DATA SHEET	
Valid from: 06.11.2024	EPIC® ZW M	

Description

- Hexagon intermediate adapter with metric connection thread.
- Enables the use of screw connections with metric threads in metric housing bores.
- The use of an O-ring makes it possible to increase the degree of protection.



General Characteristics

Series	EPIC ZW M
Version	without O-Ring
Gland Body	See Table
Protection Class (DIN EN 60529)	IP 65 (with O-Ring)
Temperature	-60 °C to 200 °C

Materials

O-Ring	NBR
Gland Body	Brass
Oberflächenschutz	Nickel-plated


Ausführungen

EPIC-Articel No.	Description	Inner/outer thread
10016000	EPIC® ZW M20	M20
10016001	EPIC® ZW M25	M25
10016002	EPIC® ZW M32	M32
10016003	EPIC® ZW M40	M40

Creator: THB01/BU-EPIC Released: IVSE1/BU-EPIC	Document: DB10016000EN Version: 00	Page 1 of 2
---	---------------------------------------	-------------

10016000	DATA SHEET	
Valid from: 06.11.2024	EPIC® ZW M	

Technical Drawings

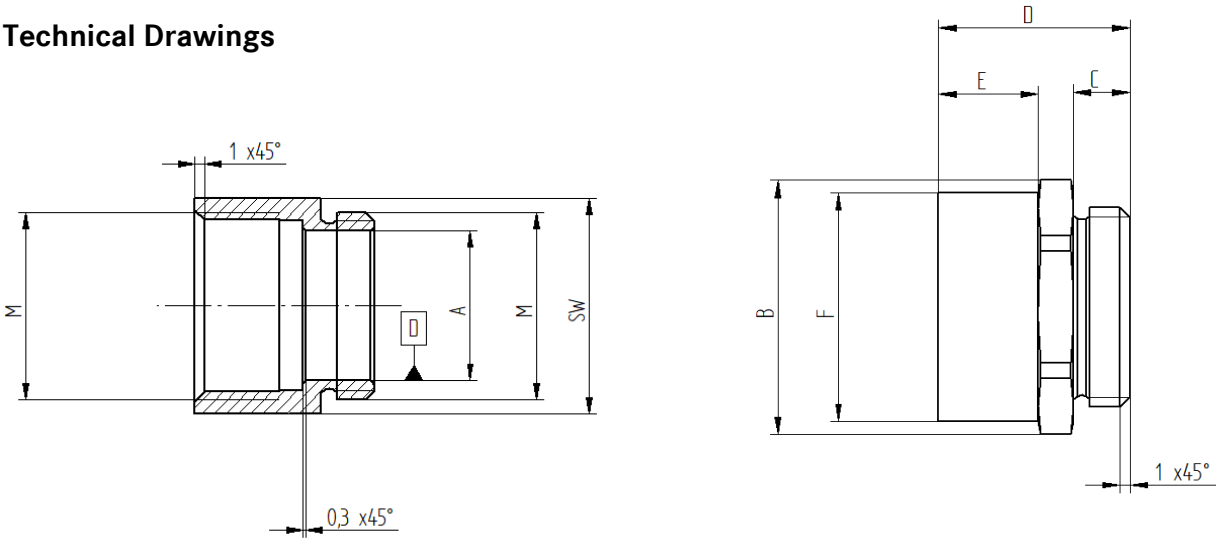

EPIC-Article No.	Description	M	SW	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	F (mm)
10016000	EPIC® ZW M20	M20x1,5	23	16	25,5	5,7	19,2	10	23
10016001	EPIC® ZW M25	M25x1,5	28	20	31	5,9	20,4	11	28
10016002	EPIC® ZW M32	M32x1,5	36	27	40	6,4	23,9	12,5	35
10016003	EPIC® ZW M40	M40	46	35	51	6,7	27,2	14,5	43



Mechanical and plant engineering



mechanical resistance



Robust



Waterproof

Anwendungsgebiete

Anlagenbau, Kunststoffindustrie

Hinweis

Die Fotografien sind nicht maßstäblich und keine detailgetreuen Abbildungen der jeweiligen Produkte.

Creator: THB01/BU-EPIC Released: IVSE1/BU-EPIC	Document: DB10016000EN Version: 00	Page 2 of 2
---	---------------------------------------	-------------