

10027810

DATA SHEET


Valid from:
30.04.2025

EPIC® H-B Q+E MOUNTING SYSTEM BOTTOM PART

**LAPP**

Description

- For mounting inserts on top-hat rails according to DIN EN 60715

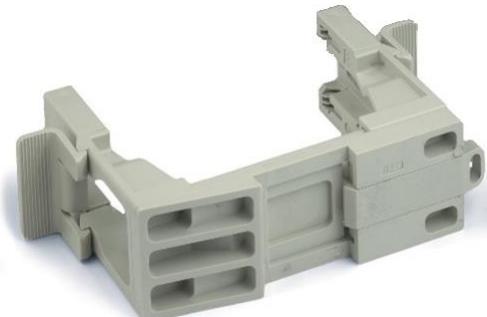

General Characteristics

Configuration

Bottom part

Series

Variable from H-B 6 to H-B 24

Temperature Range

-40°C to +100°C, short-term up to +125°C

Mechanical Characteristics

Cycle of mechanical operation

max. 50


Materials and Surfaces

Material

Polycarbonate

Flammability Class according to UL 94

V0

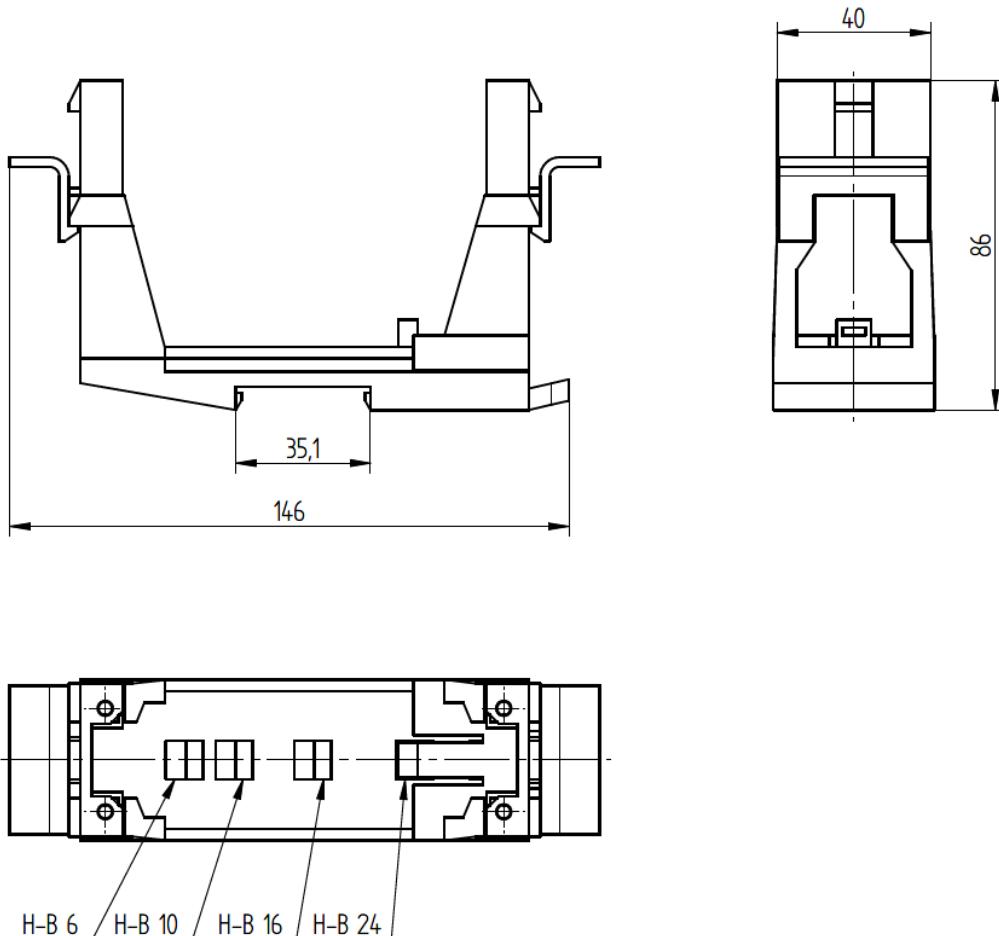Technical Drawings**Remark**

Photographs are not to scale and do not represent detailed images of the respective products.