

10161000	DATA SHEET	
Valid from: 29.06.2026	EPIC® H-B 48 AG	

Description

- The large, robust housing for two inserts in one connector
- Power and data in one connector



General Characteristics

Series	H-B 48
Version	Panel mount base
Locking	Single lever
Protection (DIN EN 60529)	IP 65 (latched)
Temperature Range	-40°C to +125°C

Materials / Surfaces

Housing	Aluminium alloy, powder-coated, grey
Lever	Stainless steel, galvanized
Sealing	NBR

Approvals

UL File Number	In preparation
----------------	----------------


cStandard

Safety Standard	IEC 61984
-----------------	-----------

Creator: LEBU1 / PDP Released: THBO1 / PDP	Document: DB10161000EN Version: 01	Page 1 of 2
---	---------------------------------------	-------------

10161000	DATA SHEET	
Valid from: 29.06.2026	EPIC® H-B 48 AG	

Technical Drawings

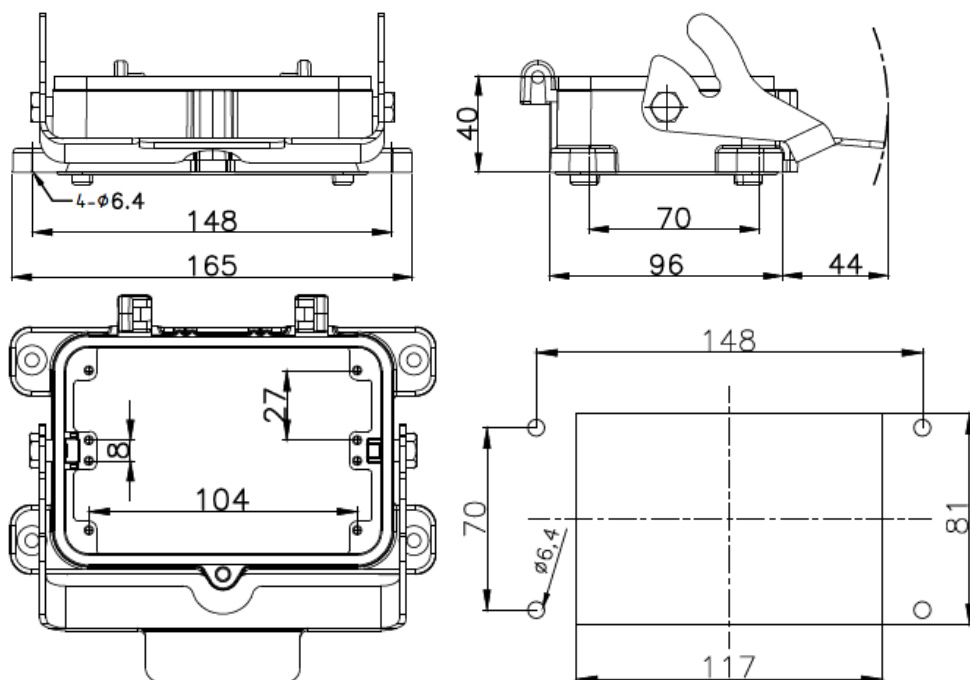

Maschinen- und Anlagenbau



Mechanische Beständigkeit



Robust



Wasserdicht

Application range

Plant engineering, Plastics industry

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Creator: LEBU1 / PDP Released: THBO1 / PDP	Document: DB10161000EN Version: 01	Page 2 of 2
---	---------------------------------------	-------------