


FLEXIMARK® Flexiprint TF

FLEXIMARK® Flexiprint TF are markers for single core marking and marking of glass fibre cables, easy and quick to install.

Info

TF1 included in FLEXIMARK® sample bag (article no. M3251010)

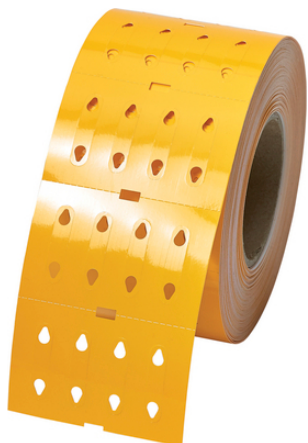

Good chemical resistance



Halogen-free



Assembly time



UV-resistant

Benefits

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

Easy to install

Application range

For single core marking

Marking of optical fibre cables

Marking before assembly

For cable cross-sections over 16.00 mm², cable ties can be used for installing single markers

Note

Easy to print via FLEXIMARK® software Flexisoft and FLEXIMARK® thermal transfer printer SQUIX, EOS5 or EOS2

Recommended ribbon: R71 110-360 resin BK (article no. 83259609)

Normal version: Up to 7 characters

L version (e.g. LF1L): Up to 15 characters

Included

Delivered as a roll of labels

FLEXIMARK® Flexiprint TF

Technical Data

| | |
|------------------------|---|
| Classification ETIM 5: | ETIM 5.0 Class-ID: EC001288 ETIM 5.0 Class-Description: Labelling material |
| Classification ETIM 6: | ETIM 6.0 Class-ID: EC001288 ETIM 6.0 Class-Description: Labelling material |
| Colour delivered: | Yellow Also available in green, blue and red |
| Material: | Halogen-free polyester Thickness: 0.175 mm |
| Temperature range: | -40°C to +125°C |

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.
FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Flexiprint TF

| Article number | Article designation | Colour | For mm ² | A (mm) | B (mm) | C (mm) | D (mm) | E (mm) | Markers / PU | PU |
|-----------------|--|--------|---------------------|--------|--------|--------|--------|--------|--------------|----|
| Small packaging | | | | | | | | | | |
| 83255011 | FLEXIMARK® Flexiprint TF0 WH600 | white | 0.25 - 0.75 | 22.9 | 5.2 | 3.9 | 13.1 | 2.4 | 600 | 1 |
| 83255012 | FLEXIMARK® Flexiprint TF1 WH600 | white | 0.75 - 1.5 | 23 | 5.2 | 4.9 | 11.2 | 3.5 | 600 | 1 |
| 83255013 | FLEXIMARK® Flexiprint TF1B WH600 | white | 1.5 - 2.5 | 25 | 5.7 | 5.9 | 11.2 | 4.2 | 600 | 1 |
| 83255014 | FLEXIMARK® Flexiprint TF2 WH600 | white | 2.5 - 6.0 | 26 | 7 | 6.5 | 11 | 5.5 | 600 | 1 |
| 83255015 | FLEXIMARK® Flexiprint TF3 WH600 | white | 6.0 - 16.0 | 41 | 11 | 10.5 | 17 | 8.4 | 200 | 1 |
| Large packaging | | | | | | | | | | |
| 83254372 | FLEXIMARK® Flexiprint TF0 YE | yellow | 0.25 - 0.75 | 22.9 | 5.2 | 3.9 | 13.1 | 2.4 | 2000 | 1 |
| 83254378 | FLEXIMARK® Flexiprint TF1 YE | yellow | 0.75 - 1.5 | 23 | 5.2 | 4.9 | 11.2 | 3.5 | 2000 | 1 |
| 83254354 | FLEXIMARK® Flexiprint TF1L YE | yellow | 0.75 - 1.5 | 34 | 5.2 | 5 | 22 | 3.5 | 2000 | 1 |
| 83254374 | FLEXIMARK® Flexiprint TF1B YE | yellow | 1.5 - 2.5 | 25 | 5.7 | 5.9 | 11.2 | 4.2 | 2000 | 1 |
| 83254359 | FLEXIMARK® Flexiprint TF1BL YE | yellow | 1.5 - 2.5 | 36 | 5.7 | 6 | 22 | 4.2 | 2000 | 1 |
| 83254375 | FLEXIMARK® Flexiprint TF2 YE | yellow | 2.5 - 6.0 | 26 | 7 | 6.5 | 11 | 5.5 | 2000 | 1 |
| 83254376 | FLEXIMARK® Flexiprint TF3 YE | yellow | 6.0 - 16.0 | 41 | 11 | 10.5 | 17 | 8.4 | 1000 | 1 |
| 83254365 | FLEXIMARK® Flexiprint TF0 WH | white | 0.25 - 0.75 | 22.9 | 5.2 | 3.9 | 13.1 | 2.4 | 2000 | 1 |

Last Update (14.07.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

 You can find the current technical data in the corresponding data sheet.
 PN 0456 / 02_03_16



FLEXIMARK® Flexiprint TF

| Article number | Article designation | Colour | For mm ² | A (mm) | B (mm) | C (mm) | D (mm) | E (mm) | Markers / PU | PU |
|----------------|--------------------------------------|--------|---------------------|--------|--------|--------|--------|--------|--------------|----|
| 83254366 | FLEXIMARK® Flexiprint TF1 WH | white | 0.75 - 1.5 | 23 | 5.2 | 4.9 | 11.2 | 3.5 | 2000 | 1 |
| 83254355 | FLEXIMARK® Flexiprint TF1L YE | white | 0.75 - 1.5 | 34 | 5.2 | 5 | 22 | 3.5 | 2000 | 1 |
| 83254367 | FLEXIMARK® Flexiprint TF1B WH | white | 1.5 - 2.5 | 25 | 5.7 | 5.9 | 11.2 | 4.2 | 2000 | 1 |
| 83254360 | FLEXIMARK® Flexiprint TF1BL WH | white | 1.5 - 2.5 | 36 | 5.7 | 6 | 22 | 4.2 | 2000 | 1 |
| 83254368 | FLEXIMARK® Flexiprint TF2 WH | white | 2.5 - 6.0 | 26 | 7 | 6.5 | 11 | 5.5 | 2000 | 1 |
| 83254369 | FLEXIMARK® Flexiprint TF3 WH | white | 6.0 - 16.0 | 41 | 11 | 10.5 | 17 | 8.4 | 1000 | 1 |

Last Update (14.07.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.
PN 0456 / 02_03_16

FLEXIMARK® Flexiprint TF

