


ELG LED panel mount buzzer

- Ø 65 mm panel-mount buzzer with LED steady/flashing beacon
- Max. 103 dB [A] sound pressure (24-240 V) / max. 89 dB [A] sound pressure (12 V AC/DC), infinitely adjustable
- High degree of protection IP 65, user-friendly connection technology
- Panel size Ø 22.5 mm/M22
- Pulsing or wobble tone with LED flashing light
- Steady tone with LED steady light
- Switching via terminal assignment
- For industrial and general applications
- Adapter available for M30.5 mm panel size



TECHNICAL DATA

Housing	Ø 65 mm, Polycarbonate black
Lens	Polycarbonate, ribbed inside amber, red
Type of mounting	any, any
Panel size	22 mm (M22) and 30.5 mm (with adapter)
Connection technology	bis 2,5 mm ²
Beacon type	LED steady beacon or LED flashing beacon
Strobe/flash frequency	2 Hz
Tone	3 Tones, 3 Tones can be switched externally, Steady tone, Pulsing tone or Wobble tone
Volume	85-103 dB (can be adjusted when panel mounted)
Tone frequency	2.800 Hz
Duty cycle	100 %
Service life	Light source: 100.000 h
Operating temperature	-25 °C / +60 °C
Degree of protection	IP65
Weight	110 g

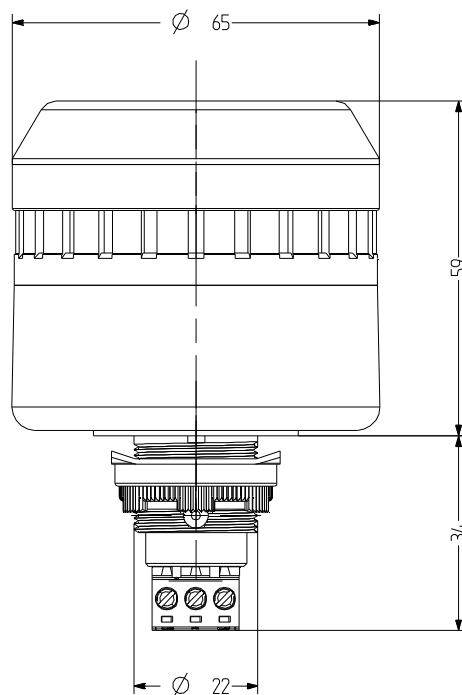

ELG

ORDER DATA

Lens colour	Nominal voltage	Voltage range (V)	Nominal current (A)	Part number
amber	12 V AC/DC	+/- 10 %	0,073	814 511 404
	24 V AC/DC	+/- 10 %	0,047	814 511 405
	110-120 V AC	+/- 10 %	0,060	814 511 310
	230-240 V AC	+/- 10 %	0,063	814 511 313
red	12 V AC/DC	+/- 10 %	0,073	814 512 404
	24 V AC/DC	+/- 10 %	0,047	814 512 405
	110-120 V AC	+/- 10 %	0,060	814 512 310
	230-240 V AC	+/- 10 %	0,063	814 512 313



ADM30

ACCESSORIES

Type	Type of accessory	Weight	Order number
ADM30	Adapter for M30.5 for 30.5 mm holes	8 g	812 500 900

TONE TABLE

Tone and light selection on terminal			
La	N	Lb	Tone and light synchronized
X	X		pulsing tone / LED flashing light
	X	X	wobble tone / LED flashing light
X	X	X	continuous tone / steady light