

POWER CORDS DATASHEET

Number of Conductors	Conductor Size	Cord Type	End 1	End 2	Length	Color Code
2	4	1	3	1	67	01
1 = 2 Conductors 2 = 3 Conductors 3 = 3 Conductors (Shielded)	2 = 12 AWG 4 = 14 AWG 6 = 16 AWG 8 = 18 AWG A = .75mm B = 1.0mm C = 1.5mm	1 = SJT 2 = SVT 3 = SPT-1 4 = SJO 5 = SJTW 6 = H03VV-F 7 = H03VVH2-F 8 = H05VV-F	0 = ROJ with Blunt-Cut, Stripped, Stripped & Tinned, or Stripped & Retained 1 = 1-15P Standard 2 = 1-15P Polarized 3 = 5-15P Straight 4 = 5-15P Right Angle 5 = 5-15P Hospital Grade Clear 6 = 5-15P Hospital Grade Gray 7 = C14 8 = 6-15P 9 = 5-20P A = C14 with European Approval B = Type C with European Approval C = Right Angle Type E with European Approval D = Type E 3 Pin with European Approval E = Type G F = Type I with Australian Approval G = Type F 2 Pin with European Approval	0 = ROJ & Stripped 1 = C13 Straight 2 = C13 Right Angle 3 = C14 4 = C-15 5 = C-19 6 = C-17 7 = 5-15R 8 = C-13	10 = 1' 18 = 1'8" 25 = 2.5M 33 = 3'3" 50 = 5'0" 60 = 6'0" 67 = 6'7" 76 = 7'6" 80 = 8'0" 90 = 9'0" 910 = 9'10" 100 = 10'0" 140 = 14'0" 160 = 16'0" 250 = 25'0"	01 = Black 02 = Brown 03 = Gray 05 = White


POPULAR END TYPES

6-15P C13 C14 C-13 Hospital Grade C-13 Right Angle TYPE C TYPE E/F TYPE G



PARALLEL CORDS

CABLED CORDS

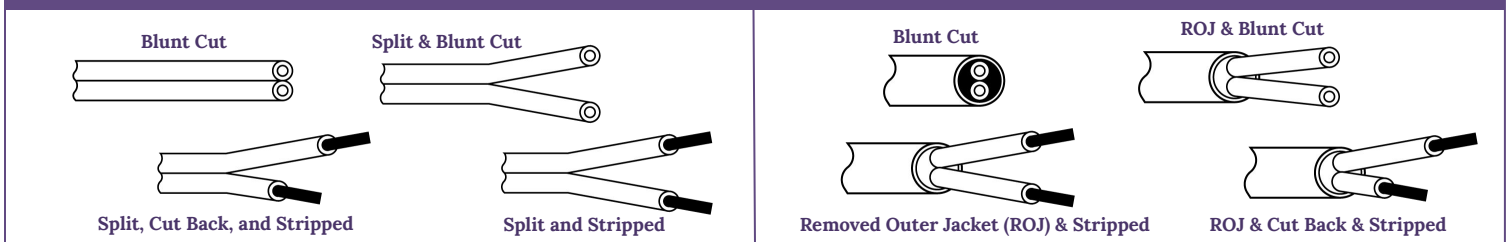



NORTH AMERICAN POWER CORDS

Part Number	AWG	Cord Type	Length (ft, in)	End 1	End 2	Current Rating (120VAC)
2 Conductor Power Cords						
18320-90-01	18	SPT-1	9'0"	1-15P	ROJ & Stripped	10A
3 Conductor Power Cords						
24101-250-01	14	SJT	25'	C13	Stripped & Retained	15A
24130-67-01	14	SJT	6'7"	5-15P	ROJ & Stripped	15A
24130-910-01	14	SJT	9'10"	5-15P	Stripped & Tinned	15A
26180-60-01	16	SJT	6'0"	6-15P	ROJ & Stripped	13A
26130-67-01	16	SJT	6'7"	5-15P	ROJ & Stripped	13A
26130-80-01	16	SJT	8'0"	5-15P	ROJ & Stripped	13A
26130-910-01	16	SJT	9'10"	5-15P	ROJ & Stripped	13A
28230-18-01	18	SVT	1'8"	5-15P	ROJ & Stripped	13A
28130-67-01	18	SJT	6'7"	5-15P	ROJ & Stripped	10A
28230-67-01	18	SVT	6'7"	5-15P	Stripped & Retained	10A
28130-80-01	18	SJT	8'0"	5-15P	Blunt-Cut Wires	10A
28130-910-01	18	SJT	9'10"	5-15P	ROJ & Stripped	10A
28230-910-01	18	SVT	9'10"	5-15P	Blunt-Cut Wires	10A
28180-910-01	18	SJT	9'10"	6-15P	ROJ & Stripped	13A

STANDARDS & APPROVALS



Product specifications may change without prior notification

Revised 2/21/24

NORTH AMERICAN POWER CORDS

Part Number	AWG	Cord Type	Length (ft, in)	End 1	End 2	Current Rating (120VAC)
3 Conductor Power Cords: 5-15P to C13						
24131-67-01	14	SJT	6'7"	NEMA 5-15P	C13	15A
24131-910-01	14	SJT	9'10"	NEMA 5-15P	C13	15A
26131-67-01	16	SJT	6'7"	NEMA 5-15P	C13	13A
26131-76-01	16	SJT	7'6"	NEMA 5-15P	C13	13A
26131-910-01	16	SJT	9'10"	NEMA 5-15P	C13	13A
28131-67-01	18	SJT	6'7"	NEMA 5-15P	C13	10A
28131-76-01	18	SJT	7'6"	NEMA 5-15P	C13	10A
28231-76-01	18	SVT	7'6"	NEMA 5-15P	C13	10A
28131-910-01	18	SJT	9'10"	NEMA 5-15P	C13	10A
3 Conductor Power Cords: 5-15P to C13 Right Angle						
26132-76-01	16	SJT	7'6"	NEMA 5-15P	C13 RIGHT ANGLE	13A
28132-76-01	18	SJT	7'6"	NEMA 5-15P	C13 RIGHT ANGLE	10A
28232-76-01	18	SVT	7'6"	NEMA 5-15P	C13 RIGHT ANGLE	10A
28132-910-01	18	SJT	9'10"	NEMA 5-15P	C13 RIGHT ANGLE	10A
3 Conductor Power Cords: 6-15P to C13						
26181-67-01	16	SJT	6'7"	NEMA 6-15P	C13	13A

STANDARDS & APPROVALS



Product specifications may change without prior notification

Revised 2/21/24

NORTH AMERICAN POWER CORDS

Part Number	AWG	Cord Type	Length (ft, in)	End 1	End 2	Current Rating (120VAC)
3 Conductor Power Cords: C14 to Blunt-Cut Wires						
26170-33-01	16	SJT	3'3"	C14	Stripped & Retained	15A
3 Conductor Power Cords: C13 to Blunt-Cut Wires						
26101-33-01	16	SJT	7'6"	Stripped & Retained	C13	13A
3 Conductor Power Cords: C14 to C13						
26171-33-01	16	SJT	3'3"	C14	C13	15A
26171-67-01	16	SJT	6'7"	C14	C13	15A
26171-910-01	16	SJT	9'10"	C14	C13	15A
28171-33-01	18	SJT	3'3"	C14	C13	15A
3 Conductor Power Cords: C14 to C13 Right Angle						
26172-10-01	16	SJT	1'0"	C14	C13 RIGHT ANGLE	13A
3 Conductor Hospital Grade Power Cords: 5-15P to C13						
26151-80-03	16	SJT	8'0"	5-15P	C13	13A
26151-100-03	16	SJT	10'0"	5-15P	C13	13A
26161-100-03	16	SJT	10'0"	5-15P	C13	13A
26161-140-03	16	SJT	14'0"	5-15P	C13	13A
28151-80-03	18	SJT	8'0"	5-15P	C13	10A
28151-100-03	18	SJT	10'0"	5-15P	C13	10A
28161-80-03	18	SJT	8'0"	5-15P	C13	10A

STANDARDS & APPROVALS





AUDIO
TECHNOLOGIES®

INTERNATIONAL POWER CORDS

Part Number	mm	Cord Type	Length (m)	End 1	End 2	Current Rating (250VAC)
3 Conductor United Kingdom Power Cords						
2B8E825-01	3x1.0	H05VV-F	2.5m	TYPE G	C13	10A
3 Conductor European Power Cords						
2B8A825-01	3x1.0	H05VV-F	2.5m	C14	C13	10A
2B8C825-01	3x1.0	H05VV-F	2.5m	TYPE E Right Angle	C13	10A
2B8D025-01	3x1.0	H05VV-F	2.5m	TYPE E	ROJ & Stripped	10A
2B8D825-01	3x1.0	H05VV-F	2.5m	TYPE E	C13	10A

STANDARDS & APPROVALS



Product specifications may change without prior notification

Revised 2/21/24

Io Audio Technologies® is a registered trademark of Knight Electronics, Inc.
10557 Metric Dr. Dallas, Tx 75243 | 214-340-0265 | 800-323-2439 | Fax: 214-340-5870 | www.ioaudiotechologies.com