

6

5

4

3

2

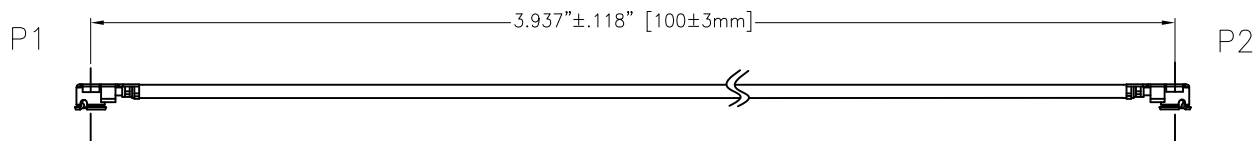
1

APPROVED: _____

DATE: _____ TITLE: _____

CUSTOM CABLE ASSEMBLIES ARE
NON-CANCELLABLE/NON-RETURNABLE

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/21/20	

**SPECIFICATIONS:****Connector:**

P1= I-PEX Connector

P2= I-PEX Connector

Cable:

Ø0.81mm Coaxial Cable, Color: Black

Electrical:

Impedance: 50 ohms

Frequency range: DC-6 GHz

Electrical Test:All Assemblies must be 100% Tested for
Shorts, Open, Continuity, and Physical Appearance.**Environmental:**

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED INCHES HOLES .X ± .10 Ø.X ± .10 .XX ± .020 Ø.XX ± .015 .XXX ± .015 Ø.XXX ± .010			ADAM TECH INTERCONNECTS 909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710	
APPROVALS		DATE		
DRAWN	LH	9/21/20		
CHECKED	RC	9/21/20		
APPROVED				
TITLE				
CUSTOM CABLE ASSEMBLY, IPEX PLUG TO IPEX PLUG WITH OD 0.81MM CABLE				
SIZE	PART NO.			REV.
X	CA-DKCA1-100LQ-I010			-
REF:	S00291T		SCALE:	NTS
		SHEET		1 OF 1