

6

5

4

3

2

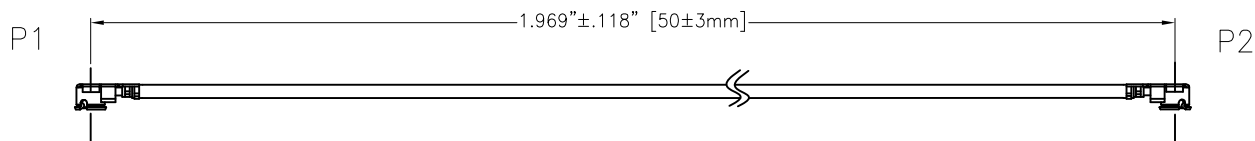
1

APPROVED: _____

DATE: _____ TITLE: _____

CUSTOM CABLE ASSEMBLIES ARE
NON-CANCELLABLE/NON-RETURNABLE

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/21/20	

**SPECIFICATIONS:****Connector:**

P1= I-PEX Connector

P2= I-PEX Connector

Cable:

Ø0.81mm Coaxial Cable, Color: Black

Electrical:

Impedance: 50 ohms

Frequency range: DC-6 GHz

Electrical Test:All Assemblies must be 100% Tested for
Shorts, Open, Continuity, and Physical Appearance.**Environmental:**

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED INCHES HOLES .X ± .10 Ø.X ± .10 .XX ± .020 Ø.XX ± .015 .XXX ± .015 Ø.XXX ± .010			ADAM TECH INTERCONNECTS		909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710	
APPROVALS			TITLE			
DATE			CUSTOM CABLE ASSEMBLY, IPEX PLUG TO IPEX PLUG WITH OD 0.81MM CABLE			
DRAWN		LH				9/21/20
CHECKED		RC				9/21/20
APPROVED						
			SIZE X	PART NO. CA-DKCA1-50LQ-1010		REV. -
REF: S00291T			SCALE: NTS		SHEET 1 OF 1	