
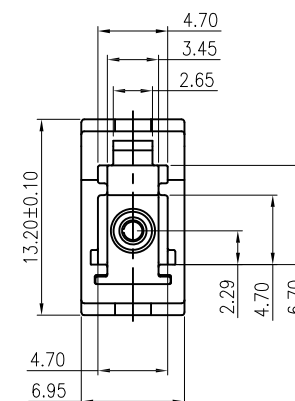
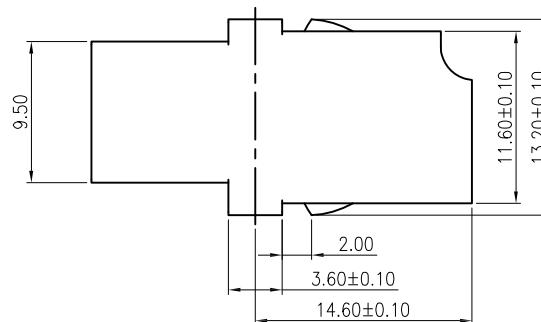
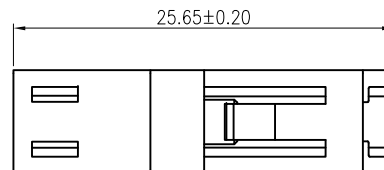


APPROVED: _____
 DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/8/20	

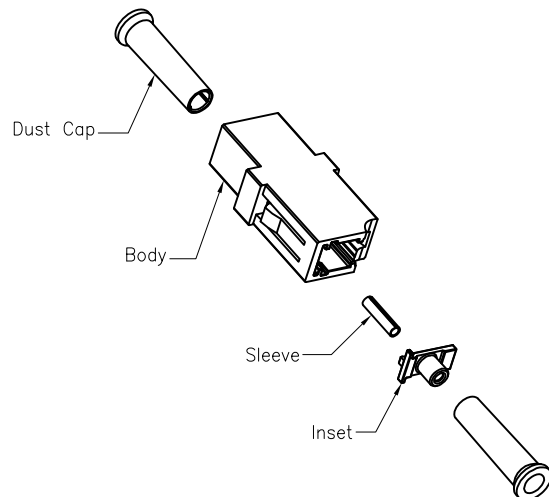

SPECIFICATIONS:

Material:
 Housing: PBT, rated UL 94V-0, Color: See Chart
 Cap: PP, rated UL 94V-0, Color: White
 Sleeve: Zirconia Ceramic
 Electrical:
 Standards of IEC 61754-20, YD/T 1272.1-2003
 Repeatability: 500 min times
 Insertion loss: 0.2dB max
 Interchangeability: 0.2dB
 Temperature Rating:
 Operating temperature: -40°C to +85°C
 Environmental:
 Lead free, RoHS compliant.



OPLC1BNNC1NA	PBT Beige	PP White
OPLA1BNNC1NA	PBT Green	PP White
OPLB1BNNC1NA	PBT Blue	PP White
Part name	Material、Color	CAP Color

UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE MILLIMETERS TOLERANCES: EXCEPT AS NOTED MM ANGLE X. ± 0.35 X.* ± 2° .X ± 0.30 .X* ± 1° .XX ± 0.25 .XX* ± 0.5° .XXX ± 0.15 .XXX* ± 0.5°			ADAM TECH INTERCONNECTS 909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710		
APPROVALS DRAWN OW 9/8/20 CHECKED JL 9/8/20 APPROVED			TITLE OPTICAL LC ADAPTERS, APC&PC&MM, 1 PORTS SHORT EARS, WITH LC DUST CAP		
SIZE X			PART NO. OPLX1BNNC1NA		REV. -
REF: S00005C		SCALE: NTS	SHEET 1 OF 1		