
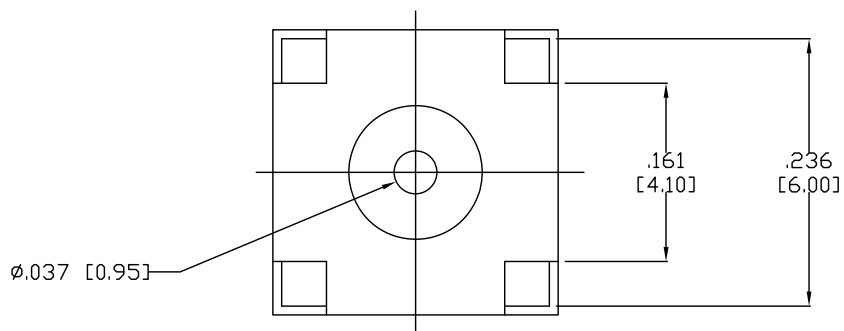


APPROVED: _____
DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-	7375	RELEASED	12/15/06	

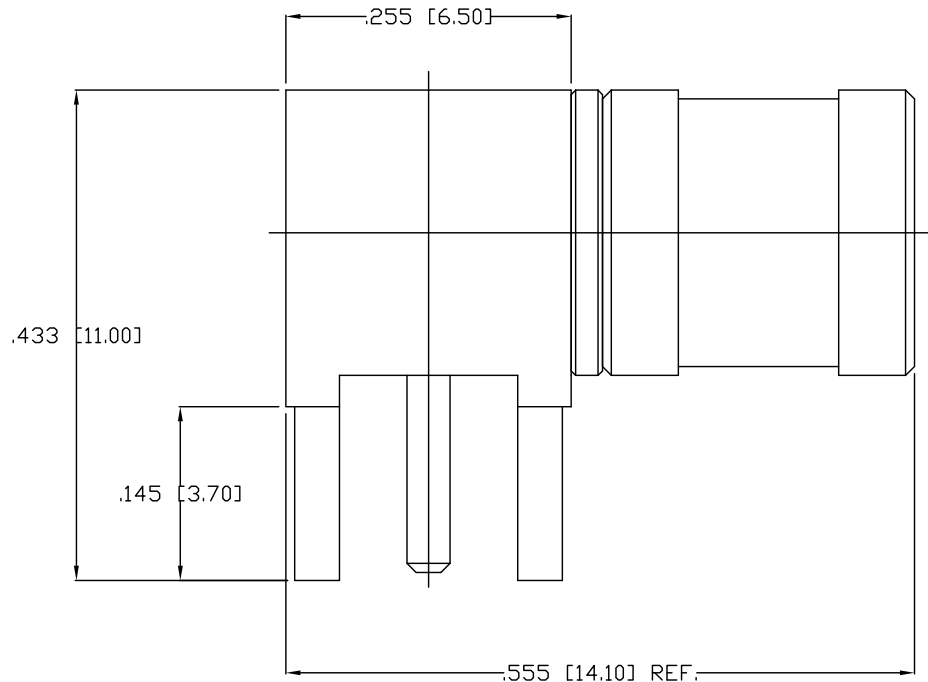

3	INSULATOR	TEFLON	1	WHITE
2	PIN	BRASS	1	GOLD
1	BODY	BRASS	1	GOLD
ITEM	DESCRIPTION	MAT'L	QTY	PLATING

SPECIFICATIONS:

Electrical:

Nominal Impedance: 50 ohms

Frequency range: 0-4 GHz

Maximum peak voltage: 500V

Insulation resistance: 5000 Mohm min @ 500 VDC

Dielectric withstanding voltage: 1500 VAC rms

Environmental:

Lead free, RoHS compliant.

Recommended soldering temp: 235°C for 5 sec.



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE MM [INCHES]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES
.X ± .10 Ø.X ± .10
.XX ± .020 Ø.XX ± .015
.XXX ± .015 Ø.XXX ± .010

APPROVALS		DATE
DRAWN	BW	12/15/06
CHECKED		
APPROVED		

ADAM TECH

909 Rahway Avenue, Union, NJ 07083
Phone: 908-687-5000 Fax: 908-687-0214

TITLE
RIGHT ANGLE SMB PLUG
PCB MOUNT 50 OHM

SIZE X	PART NO. RF3-04-T-00-50-G	REV. -
REF:		SCALE: NTS
		SHEET 1 OF 1