


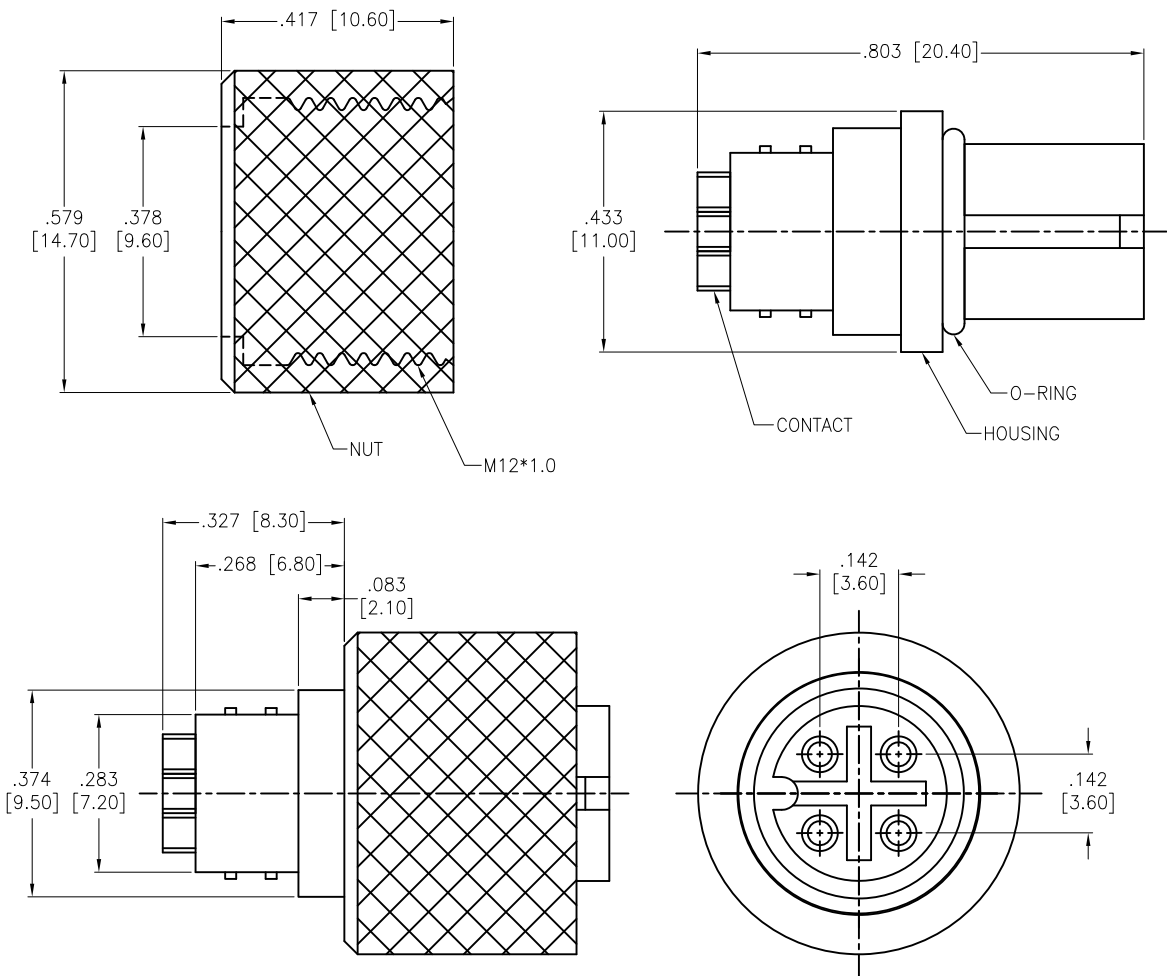

SPECIFICATIONS:

Material:

Housing: PBT, Color: Black

Contacts: Brass, 10u" Gold over Nickel plated

Nut: Brass, Nickel plated

O-ring: EPDM, Color: Black

Electrical:

Voltage rating: 125 V

Current rating: 5 A

Water Proof: IP67

Temperature Rating:

Operating temperature: -40°C to +85°C

Environmental:

Lead free, RoHS compliant.



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED				≡ ADAM TECH INTERCONNECTS		909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710	
INCHES HOLES .X ± .10 Ø.X ± .10 .XX ± .020 Ø.XX ± .015 .XXX ± .015 Ø.XXX ± .010							
APPROVALS		DATE		TITLE WATERPROOF CONNECTOR, FEMALE, M12, A-CODING, SEMI-FINISHED PRODUCT			
DRAWN	LH	9/5/19					
CHECKED	RC	9/5/19		SIZE X			
APPROVED							
REF: S00298T				SCALE: NTS		SHEET 1 OF 1	

PART NO. SD-PMA04-FFTS4		REV. -
----------------------------	--	-----------