



Part Number: D3I4013Y-4K


Electrical Specifications

Frequency Range (GHz):	4.35 – 13.15
Isolation (dB):	12 MIN
Insertion Loss (dB):	1.0 MAX
Return Loss (dB):	12 MIN
Forward Power (W):	20 AVG 30 PK
Reflective Power (W):	2 AVG

Mechanical/Environmental Specifications

Connector Type:	SMA
Connector Body:	Passivated stainless steel
Connector Pin:	Gold plated copper
Load Body:	Brass
Magnetic Shunt:	Nickel plated CRS
Optimized Temperature:	< 4K
Weight (oz)	2.0 MAX

D3I4013Y-4K-2 Dimensions

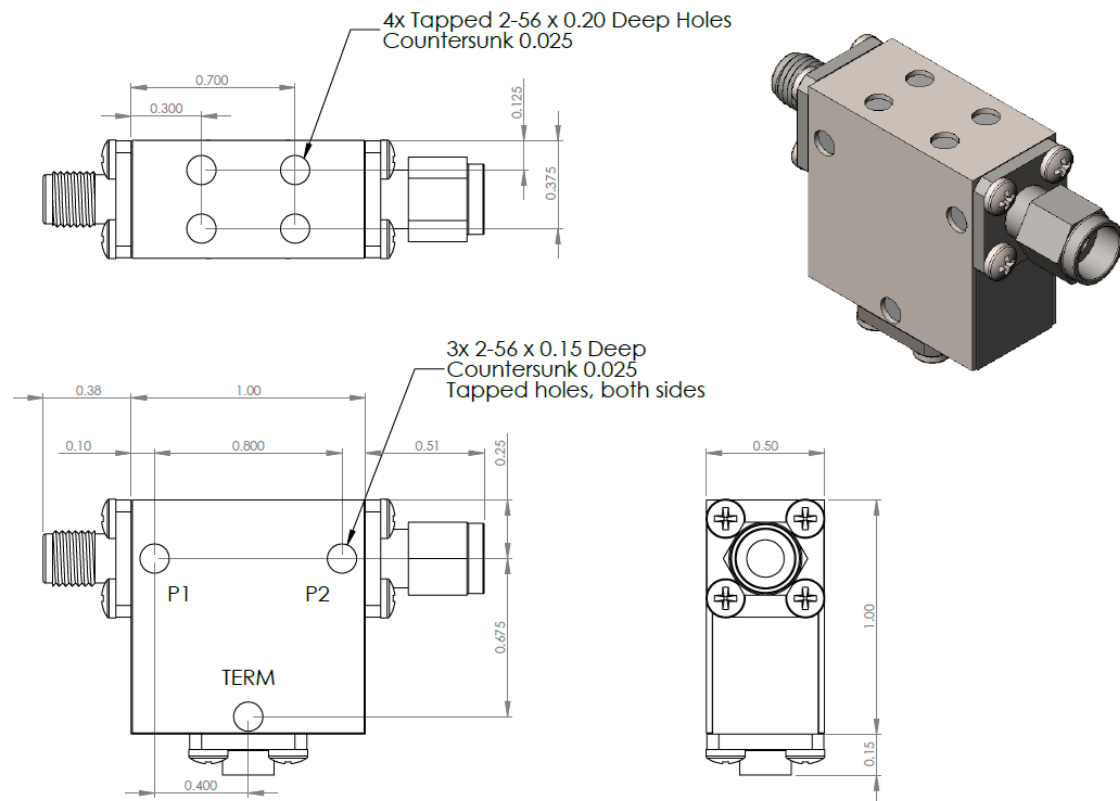

Dimensions are in inches
Tolerance
XX ±0.03
XXX ±0.010

Type of Device	PN Suffix	Connector Configuration Port 1 / Port 2	PN Example
Single and Dual Junction Isolator, 2-Port Device Port 1 / Port 2	N/A	Female / Female	D3I4013Y-4K
	-1	Male / Female	D3I4013Y-4K-1
	-2	Female / Male	D3I4013Y-4K-2
	-3	Male / Male	D3I4013Y-4K-3



MEASURED DATA

Part Number: D3I4013Y-4K, Measured at 4K

