


Product data sheet

Characteristics

DE9PEM20010

M20 x 1.5 cable gland for use with Ø 6 to 12 mm cable

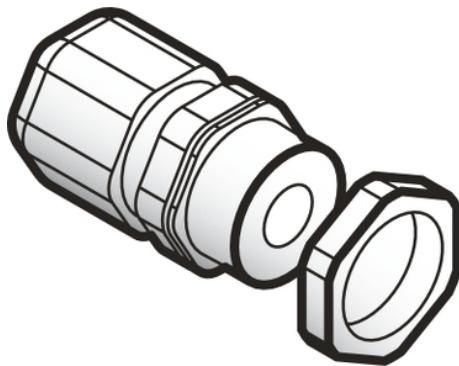

Main

Accessory / separate part category	Separate parts
Accessory / Separate Part Type	Cable gland
Thread type	M20 x 1.5
Accessory / separate part destination	Ø 6 to 12 mm unarmoured cable
Sale per indivisible quantity	10

Complementary

Housing material	Plastic
Material	PA66
Color	Gray RAL 7035)
Net Weight	0.02 lb(US) (0.01 kg)

Environment

IP Degree of Protection	IP68
Product Certifications	CE CSA UR

Ordering and shipping details

Category	22449-LIMIT SWITCHES,ACCESSORIES
Discount Schedule	T
GTIN	3389119079037
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.14 in (2.9 cm)
Package 1 Width	1.18 in (3 cm)
Package 1 Length	1.18 in (3 cm)
Package 1 Weight	0.42 oz (12 g)
Unit Type of Package 2	BAG
Number of Units in Package 2	10
Package 2 Height	1.57 in (4 cm)
Package 2 Width	5.91 in (15 cm)
Package 2 Length	5.91 in (15 cm)
Package 2 Weight	4.44 oz (126 g)
Unit Type of Package 3	S01
Number of Units in Package 3	100
Package 3 Height	5.91 in (15 cm)

Package 3 Width	5.91 in (15 cm)
Package 3 Length	15.75 in (40 cm)
Package 3 Weight	3.20 lb(US) (1.45 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Diisobutyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	 REACH Declaration
EU RoHS Directive	Not applicable, out of EU RoHS legal scope

Contractual warranty

Warranty	18 months
----------	-----------