

# Product data sheet

## Characteristics

# XXZPB100

Teach mode pushbutton, selection of detection window, for ultrasonic sensor



### Main

Accessory / separate part designation	Teach mode push-button
Accessory / separate part destination	Ultrasonic sensor
Accessory / separate part category	Sensor accessories
Accessory / Separate Part Type	Push-button

### Complementary

Product Compatibility	XX518A3.AM12 XX7V1A1.AM12
Electrical connection	1 male connector M12 3 pins straight 1 female connector 5 pins straight
Net Weight	0.08 lb(US) (0.035 kg)

### Ordering and shipping details

Category	22490-SENSORS-ULTRASONIC (XX5,6)
Discount Schedule	DS2
GTIN	3389110704211
Returnability	Yes
Country of origin	FR

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.61 in (4.1 cm)
Package 1 Width	2.60 in (6.6 cm)
Package 1 Length	3.78 in (9.6 cm)
Package 1 Weight	1.73 oz (49.0 g)
Unit Type of Package 2	S02
Number of Units in Package 2	30
Package 2 Height	5.91 in (15.0 cm)
Package 2 Width	11.81 in (30.0 cm)
Package 2 Length	15.75 in (40.0 cm)
Package 2 Weight	4.01 lb(US) (1.818 kg)

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Diisobutyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	 <a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	 <a href="#">Yes</a>
Environmental Disclosure	 <a href="#">Product Environmental Profile</a>
Circularity Profile	 <a href="#">End Of Life Information</a>


## Contractual warranty

Warranty	18 months
----------	-----------

---


Dimensions

---

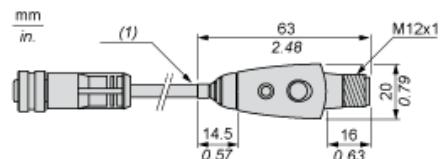

(1) Cable, length: 152 mm.

Wiring for Teaching of Detection Window

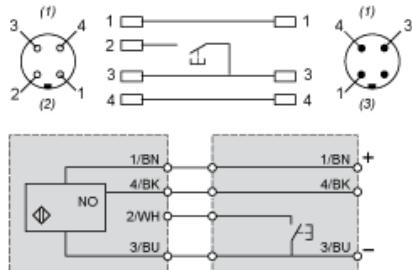

(1) M12 female connector

(2) Sensor side

(3) Output

BN Brown

WH White

BU Blue

BK Black