

Product data sheet

Characteristics

XZCPB1241L5

Pre wired connectors XZ, elbowed female, M12
4 pins, shielded cable PUR 5 m



Main

| | |
|------------------------------------|----------------------------------|
| Range of Product | Telemecanique Cabling components |
| Accessory / separate part category | Cabling accessory |
| Accessory / Separate Part Type | Pre-wired connectors |
| Series name | Application |

Complementary

| | |
|--------------------------------|--------------------------------------|
| Electrical connection | Elbowed female connector M12, 4 pins |
| Cable connector fixing | Screw-on |
| Collar material | Metal |
| Status LED | Without |
| Cable length | 16.40 ft (5 m) |
| Cable outer diameter | 0.23 in (5.9 mm) |
| Cable composition | 4 x 0.34 mm ² |
| Wire insulation material | PUR shielded cable) |
| [Ue] rated operational voltage | 250 V AC 300 V DC |
| Line Rated Current | 4 A |
| Contact resistance | 5000 µOhm |
| Minimum insulating resistance | 1 GΩ |
| Net Weight | 0.77 lb(US) (0.35 kg) |

Environment

| | |
|---------------------------------------|-----------------------------------|
| IP Degree of Protection | IP65 IP67 |
| Ambient air temperature for operation | -13...176 °F (-25...80 °C) static |
| Ambient Air Temperature for Storage | -13...176 °F (-25...80 °C) |

Ordering and shipping details

| | |
|-------------------|----------------------|
| Category | 22483-MACHINE CABLES |
| Discount Schedule | DS3 |
| GTIN | 3389119621779 |
| Returnability | No |
| Country of origin | CZ |

Packing Units


| | |
|------------------------------|-------------------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 0.98 in (2.5 cm) |
| Package 1 Width | 7.87 in (20.0 cm) |
| Package 1 Length | 6.89 in (17.5 cm) |

| | |
|------------------------------|------------------------|
| Package 1 Weight | 8.01 oz (227.0 g) |
| Unit Type of Package 2 | S02 |
| Number of Units in Package 2 | 15 |
| Package 2 Height | 5.91 in (15.0 cm) |
| Package 2 Width | 11.81 in (30.0 cm) |
| Package 2 Length | 15.75 in (40.0 cm) |
| Package 2 Weight | 8.24 lb(US) (3.738 kg) |

Offer Sustainability

| | |
|----------------------------|---|
| California proposition 65 | WARNING: This product can expose you to chemicals including: Diisobutyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |
| REACH Regulation | <input checked="" type="checkbox"/> REACH Declaration |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) <input checked="" type="checkbox"/> EU RoHS Declaration |
| Mercury free | Yes |
| RoHS exemption information | <input checked="" type="checkbox"/> Yes |


Dimensions

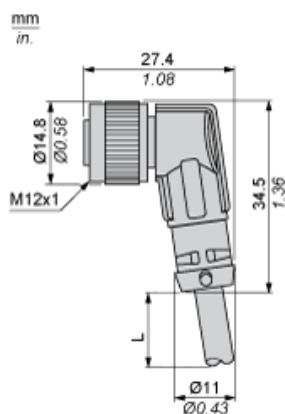

L : Length of cable

Connections and Schemes

Connector

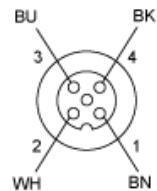

BN : Brown
BK : Black
BU : Blue
WH : White